


Technical data sheet

90° bend 60

Item no. 6043208

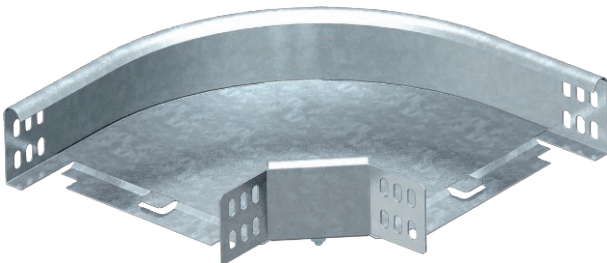

90° bend, horizontal, for all cable tray types of 60 mm side height.




St	Steel
FS	Strip galvanised

Additional product text, instruction	The fitting is shipped in an unmounted state. Including appropriate fastening material.
--------------------------------------	---

Master data

Item no.	6043208
Type	RB 90 615 FS
Description 1	90° bend
Description 2	horizontal + angle connector
Dimension	60x150
Material	Steel
Material symbol	St
Surface	Strip galvanised
Surface to DIN	DIN EN 10346
Surface symbol	FS
Smallest sales unit (VG)	1,00 Piece
Weight	88,40 kg/100 pc.

Technical data

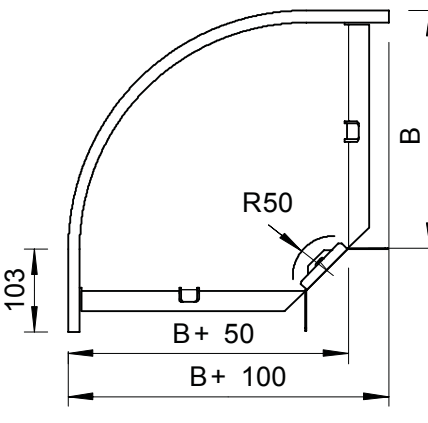	Width	150,00 mm
	Side height	60,00 mm
	Dimension B	150,00 mm
	Dimension R	50,00 mm
	Bend (angle)	90°
	Connector version	Supplied connectors
	Dimension	250 x 250 x 60 mm
	Suitable for maintaining electrical function	☐
	Mounting perforation in base	☐
	NATO hole pattern	☐
	Change of direction	Horizontal
	Rustproof steel, pickled	☐
	Side perforation	☐
	Wide-span version	☐