


RJ45 Network Cable Cat.6A U/FTP ultra flexible with inner metal jacket 2 m black

Description

This network cable by Delock can be used to connect different networking devices, e.g. a NIC to a switch or a patch panel.

Ultra flexible with inner metal jacket

The robust network cable offers an increased protection against damage and outer influences such as moisture, dust or damaging rodents. Despite the metal sheath, the cable remains bendable and high flexible.

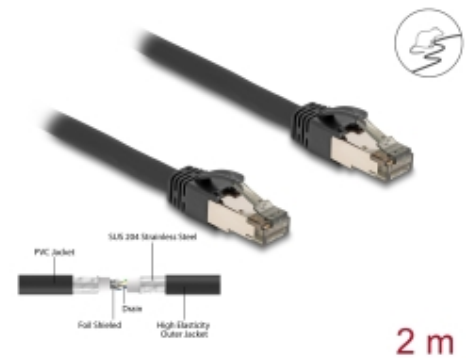

Item no. 80241

EAN: 4043619802418

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
 - 1 x RJ45 plug
 - 1 x RJ45 plug
- 1:1 connected
- Cat.6A specification
- Shielded (U/FTP)
- Environmental temperature: -20 °C ~ 60 °C
- Cable gauge: 28 AWG
- Cable diameter: ca. 7.3 mm
- Inner cable jacket material: SUS 204
- Outer cable jacket material: high elastic PVC
- Colour: black
- Length: ca. 2 m

System requirements

- A free RJ45 jack

Package content

- Patch cable

Images



General

Specification:	Cat. 6A
Style:	both sides identical

Interface

Connector 1:	1 x RJ45 male
Connector 2:	1 x RJ45 male

Technical characteristics

Operating temperature:	-20 °C ~ 60 °C
------------------------	----------------

Physical characteristics

Cable gauge:	28 AWG
Length:	2 m
Colour:	black
Cable diameter:	7.3 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de