

Cable USB 10 Gbps Type-E Key A 20 pin male > USB 10 Gbps USB Type-C™ female panel-mount 45 cm

Description

This cable by Delock can be connected to the internal USB 3.1 Gen 2 key A socket of a motherboard or a PCI Express card (e.g. [Delock 89603](#)) and can be used to extend a USB connection. The USB Type-C™ connector can be attached with two screws, e.g. on a slot bracket or a chassis with the corresponding recess. In this way, it is possible to install a USB port in an easily accessible position.



45 cm

Item no. 85326

EAN: 4043619853267

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
 - 1 x SuperSpeed USB 10 Gbps (USB 3.1 Gen 2) key A 20 pin male 90° angled >
 - 1 x SuperSpeed USB 10 Gbps (USB 3.1 Gen 2) USB Type-C™ female
- Two mounting holes for screws, spacing 20 mm, with M3 thread
- Cable gauge:
 - 28 + 30 AWG data line
 - 26 + 28 AWG power line
- Cable diameter: ca. 5 mm
- Data transfer rate up to:
 - SuperSpeed USB 10 Gbps,
 - SuperSpeed USB 5 Gbps,
 - Hi-Speed 480 Mbps,
 - Full-Speed 12 Mbps,
 - Low-Speed 1.5 Mbps
- Length incl. connectors: ca. 45 cm


System requirements

- PC with a free USB 3.1 Gen 2 key A interface

Package content

- USB cable

Images

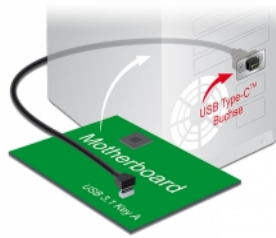

Interface

Connector 1:	1 x USB 3.2 Gen 2 key A 20 pin male
Connector 2:	1 x USB 10 Gbps USB Type-C™ female

Technical characteristics

Data transfer rate:	10 Gbps
---------------------	---------

Physical characteristics

Cable gauge:	28 AWG data line 30 AWG data line 26 AWG power line 28 AWG power line
Length:	45 cm
Cable diameter:	5 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de