

DATASHEET

CABLEARC NATURAL IMPACT-DRIVEN FLEXIBLE CABLE CLAMP

DESIGNED TO SNAP-MOUNT CABLES FAST WITH A SECURE LOW-PROFILE ARC BASE



MATERIAL FIRE RESISTANCE according to UL94V2 - self-extinguishing


RESISTANCE TO solvents, greases and oils

INSTALLATION TEMPERATURE $-5^{\circ}\text{C} \div 50^{\circ}\text{C}$



WORKING TEMPERATURE $-25^{\circ}\text{C} \div 60^{\circ}\text{C}$

MATERIAL polyamide 6.6


Cable clamp for 10 wires

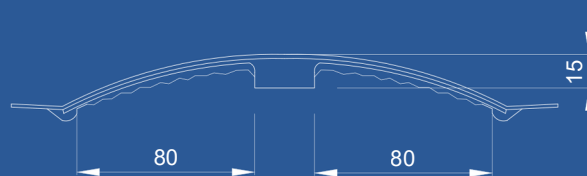

Cableclamp for 8 wires

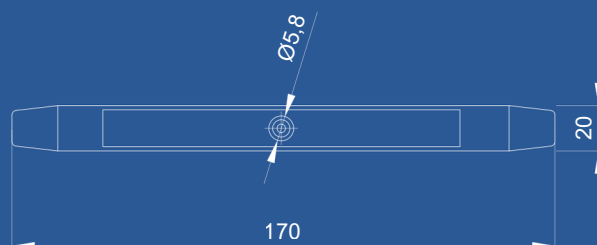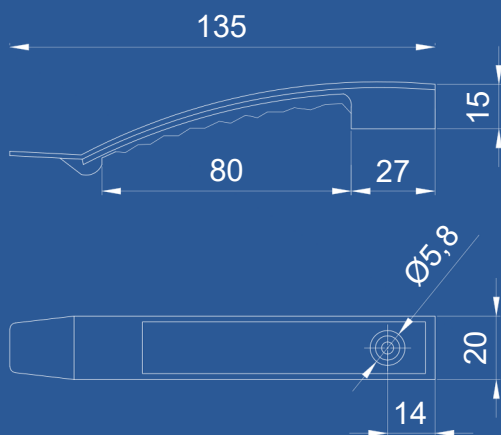

Cable clamp for 16 wires

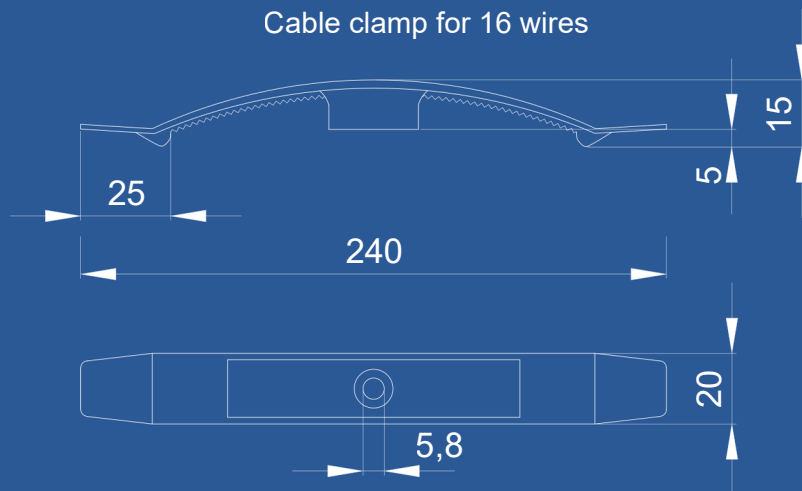

ARTICLE	NAME	CABLE SIZE	L, MM	W, MM	H, MM	HOLE Ø, MM	COLOR
TTCA8N	CableArc for 8 cables	3x1.5 mm ²	135	20	15	5,8	natural
TTCA10N	CableArc for 10 cables	3x1.5 mm ²	170	20	15	5,8	natural
TTCA16N	CableArc for 16 cables	3x1.5 mm ²	240	20	15	5,8	natural