

# USB 2.0 to 2 x serial RS-232 adapter

## Description

This EASY-USB Type-A to serial adapter by Delock provides two RS-232 DB9 interfaces for printers, measuring instruments, controllers, IoT devices etc.



**Item no. 63950**

EAN: 4043619639502

Country of origin: China

Package: Retail Box

## Technical details

- Connectors:  
1 x EASY-USB 2.0 Type-A male >  
2 x serial RS-232 DB9 male with nuts
- Chipset: ASIX MCS7820
- Databits: 5, 6, 7, 8
- Stop bits: 1, 2
- FIFO: 512 Byte buffer bi-directional
- Parity: even, odd, none, mark, space
- Flow control: none, hardware RTS / CTS, software XON / XOFF
- Signals: TxD, RxD, RTS, CTS, DTR, DSR, DCD, RI, GND
- Data transfer rate up to 460.8 Kb/s
- Supports: UHCI / OHCI / EHCI
- Serial connector with nuts
- Supports remote wake-up and power management
- Compatible with 16C450 / 16C550 UART
- 1 x ferrite core
- Length incl. connectors (L): ca. 0.6 m


## System requirements

- Linux Kernel 2.6 or above
- Windows 7/7-64/8.1/8.1-64/10/10-64
- PC or laptop with a free USB Type-A port

## Package content

- EASY-USB 2.0 to 2 x serial adapter
- Driver CD
- User manual

## Images

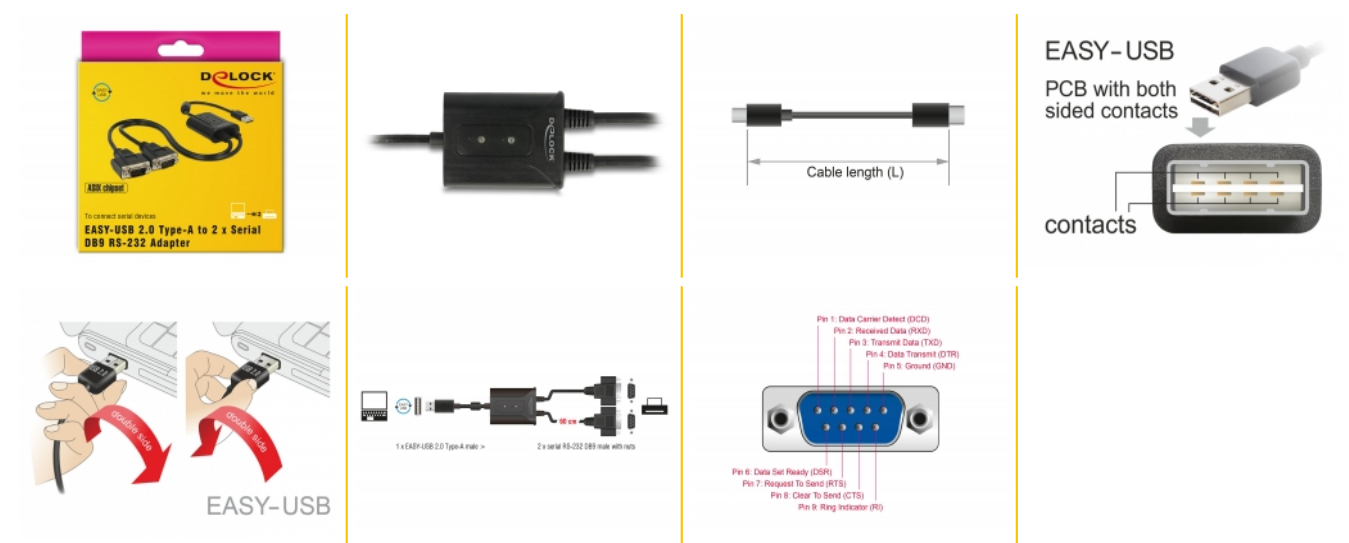

## General

|                             |                                                                                                                                                         |
|-----------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------|
| Specification:              | RS-232 (EIA / TIA)<br>USB 2.0                                                                                                                           |
| Supported operating system: | Linux Kernel 2.6 or above<br>Windows 10 32-Bit<br>Windows 10 64-Bit<br>Windows 7 32-Bit<br>Windows 7 64-Bit<br>Windows 8.1 32-Bit<br>Windows 8.1 64-Bit |

## Interface

|              |                              |
|--------------|------------------------------|
| Connector 1: | 1 x EASY-USB 2.0 Type-A male |
| Connector 2: | 2 x serial RS-232 DB9 plug   |

## Technical characteristics

|                     |                             |
|---------------------|-----------------------------|
| Chipset:            | ASIX MCS7820                |
| Data transfer rate: | 460.8 Kbps                  |
| FIFO:               | 512 Byte                    |
| Data transmission:  | asynchronous<br>full duplex |

## Physical characteristics

|                                |           |
|--------------------------------|-----------|
| Connector color:               | black     |
| Housing material:              | Plastic   |
| Cable colour:                  | black     |
| Cable length incl. connectors: | ca. 60 cm |
| Screw type:                    | #4-40 UNC |

## Manufacturer information

|             |                   |
|-------------|-------------------|
| Street      | Beeskowdamm 13/15 |
| Postal code | 14167             |

|         |                |
|---------|----------------|
| City    | Berlin         |
| Country | Deutschland    |
| E-Mail  | info@delock.de |
| Website | www.delock.de  |