


Optical Fiber loopback Adapter LC / OM1 Multi-mode beige

Description

This loopback adapter by Delock can be used for testing purposes and for testing fiber optic connections. With the loopback, the transmission capability of the optical fibers can be measured.

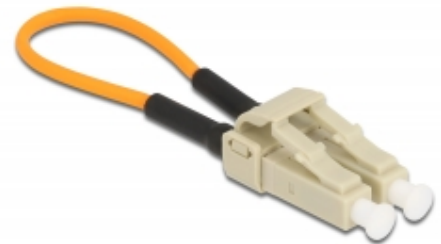

Item no. 86925

EAN: 4043619869251

Country of origin: China

Package: Zip poly bag

Technical details

- Connector:
 - 1 x LC Duplex male
- Multi-mode OM1 cable
- Fibre: 62.5/125 µm
- ~~Is not a fiber~~ Is not a fiber with dust protection cap
- Cable diameter: ca. 2 mm
- Operating temperature: -20 °C ~ 70 °C
- Colour: beige / orange
- Cable jacket material: PVC
- Dimensions (LxWxH): ca. 60 x 20 x 11 mm

Package content

- Optical fiber adapter loopback

Images



General

Specification:	OM1
----------------	-----

Interface

Connector:	1 x LC Duplex male
------------	--------------------

Technical characteristics

Operating temperature:	-20 °C ~ 70 °C
------------------------	----------------

Physical characteristics

Material:	PVC
Length:	60 mm
Width:	20 mm
Height:	11 mm
Colour:	orange beige
Cable diameter:	3 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

