

## 1160 i VDE Insulated screwdriver for slotted screws, 1 x 5.5 x 125 mm

### Kraftform Comfort VDE



|                        |               |                               |              |
|------------------------|---------------|-------------------------------|--------------|
| <b>EAN:</b>            | 4013288110176 | <b>Size:</b>                  | 223x33x33 mm |
| <b>Part number:</b>    | 05031587001   | <b>Weight:</b>                | 72 g         |
| <b>Article number:</b> | 1160 i VDE    | <b>Country of origin:</b>     | CZ           |
|                        |               | <b>Customs tariff number:</b> | 82054000     |

- Insulated Kraftform Comfort VDE blades for safe working up to 1,000 volts
- Multi-component Kraftform handle for fast and low-fatigue working
- Handle markings simplify finding and sorting of tools
- The Wera Black Point tip offers an exact fit and optimum corrosion protection
- Individually tested

High quality Kraftform Comfort VDE screwdriver. Multi-component Kraftform handle for fast and low-fatigue working. The Wera Black Point tip and a complex hardening process ensure a long service life of the tip, enhanced corrosion protection and an exact fit. Individual testing in a water bath at 10,000 volts so as to ensure safe working at the permitted voltage of 1,000 volts. The hexagonal anti-roll feature prevents any bothersome rolling away at the workplace. Handle markings for simplified finding and sorting of the tool.

#### Web link

[https://products.wera.de/en/tools\\_for\\_electricians\\_kraftform\\_comfort\\_vde\\_1160\\_i\\_vde.html](https://products.wera.de/en/tools_for_electricians_kraftform_comfort_vde_1160_i_vde.html)

Wera - 1160 i VDE  
05031587001 - 4013288110176


Wera Werkzeuge GmbH  
Korzerter Straße 21-25  
D-42349 Wuppertal  
Tel: +49 (0)2 02 / 40 45-0  
E-Mail: [info@wera.de](mailto:info@wera.de)

**Kraftform Comfort VDE**

**Individually tested**




The ergonomic introduction to convenient screwdriving. Handle with Kraftform geometry and blade made from power bit material with Black Point tip for precise fit – and they are even VDE-tested, too.

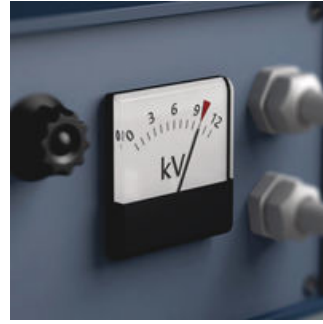


The individual testing at 10,000 volts, in accordance with IEC 60900, ensures safe working with loads up to 1,000 volts.

**Kraftform Comfort Handle**

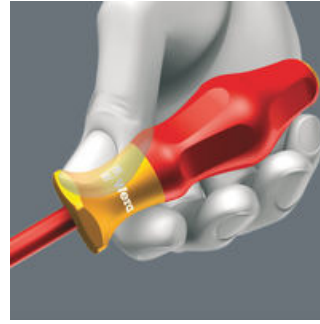

The multi-component Kraftform handle for quick and low-exertion working.

**Non-roll feature**

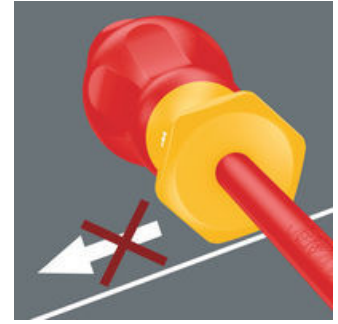

The hexagonal non-roll feature prevents any rolling away at the workplace.

**Identification marking**



The screw symbol and tip size identification markings on the handle make it easier to find the right screwdriver in the tool case, or at the workplace.

**Wera Black Point tip**



The Wera Black Point tip and a refined hardening process ensure long service life of the tip, improved corrosion protection and an exact fit.

**Web link**

[https://products.wera.de/en/tools\\_for\\_electricians\\_kraftform\\_comfort\\_vde\\_1160\\_i\\_vde.html](https://products.wera.de/en/tools_for_electricians_kraftform_comfort_vde_1160_i_vde.html)

Wera - 1160 i VDE  
05031587001 - 4013288110176

Wera Werkzeuge GmbH  
Korzerter Straße 21-25  
D-42349 Wuppertal  
Tel: +49 (0)2 02 / 40 45-0  
E-Mail: [info@wera.de](mailto:info@wera.de)

## Kraftform Comfort VDE

Further versions in this product family:

|                    | <br>mm | <br>mm | <br>mm | <br>mm | <br>inch | <br>inch |
|--------------------|-----------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------|
| 05031580001        | 0.4                                                                                     | 2.5                                                                                     | 80                                                                                      | 81                                                                                       | 3/32                                                                                        | 3 1/8                                                                                       |
| 05031581001        | 0.5                                                                                     | 3.0                                                                                     | 100                                                                                     | 81                                                                                       | 1/8                                                                                         | 4                                                                                           |
| 05031582001        | 0.6                                                                                     | 3.5                                                                                     | 100                                                                                     | 81                                                                                       | 9/64                                                                                        | 4                                                                                           |
| 05031583001        | 0.8                                                                                     | 4.0                                                                                     | 100                                                                                     | 98                                                                                       | 5/32                                                                                        | 4                                                                                           |
| 05031584001        | 0.8                                                                                     | 4.0                                                                                     | 150                                                                                     | 98                                                                                       | 5/32                                                                                        | 6                                                                                           |
| <b>05031587001</b> | <b>1.0</b>                                                                              | <b>5.5</b>                                                                              | <b>125</b>                                                                              | <b>98</b>                                                                                | <b>7/32</b>                                                                                 | <b>5</b>                                                                                    |
| 05031585001        | 1.0                                                                                     | 5.5                                                                                     | 200                                                                                     | 98                                                                                       | 7/32                                                                                        | 8                                                                                           |
| 05031588001        | 1.2                                                                                     | 6.5                                                                                     | 150                                                                                     | 105                                                                                      | 1/4                                                                                         | 6                                                                                           |
| 05031589001        | 1.2                                                                                     | 8.0                                                                                     | 175                                                                                     | 112                                                                                      | 5/16                                                                                        | 7                                                                                           |

## Web link

[https://products.wera.de/en/tools\\_for\\_electricians\\_kraftform\\_comfort\\_vde\\_1160\\_i\\_vde.html](https://products.wera.de/en/tools_for_electricians_kraftform_comfort_vde_1160_i_vde.html)

Wera - 1160 i VDE

05031587001 - 4013288110176

Wera Werkzeuge GmbH

Korzerter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: [info@wera.de](mailto:info@wera.de)