


TYPE 3288

INSULATED MOUNTING RECEPTACLE Ø4MM PLUG / M4 THREADED
STUD WITH HEX NUTS TERMINAL, PRESS FIT FIXING
**EMBASE DE TERRE ISOLÉE FICHE Ø4MM / RACCORD FILETAGE
M4 AVEC ÉCROUS, FIXATION PAR PRESSION**
**ISOLIERTE ERDUNGS- UND MASSEDOSE Ø4MM STECKER /
M4 GEWINDEBOLZEN MIT MUTTERN, BEFESTIGUNG DURCH
EINPRESSEN**

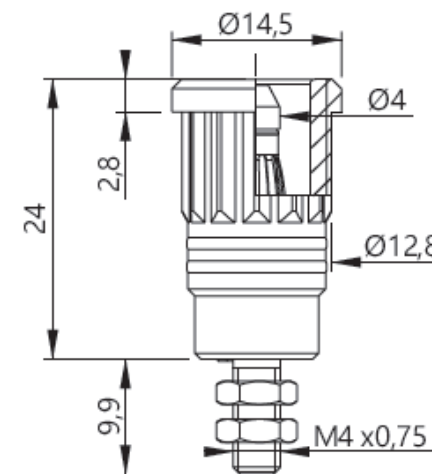

Reference
Référence 3288
Bestell-Nr

Rated voltage Tension assignée <i>Bemessungsspannung</i>	Rated current Intensité assignée <i>Bemessungsstrom</i>	Contact parts Contacts <i>Kontaktteile</i>	Insulation Isolant <i>Isolierteile</i>	Colours [#] Couleurs [#] <i>Farben [#]</i>
1000 V CAT III	36A	Ni coated brass Laiton nickelé <i>Messing vernickelt</i>	PA6.6	J/V 

This receptacle does not comply with our standard Ø4mm plugs
Cette embase n'est pas compatible avec nos fiches Ø4mm mâles standard
Diese Dose ist mit unseren Standard Ø4mm-Steckern nicht kompatibel