

# PRODUCT DATA SHEET

**3925s**

**Plug-in distributors partially insulated – 3925 S Ms sn PVC 6.3x0.8**



## Product Overview

<b>SKU</b>	<b>3925s</b>
<b>Part description</b>	<b>Plug-in distributors partially insulated</b>
<b>Part designation</b>	<b>3925 S Ms sn PVC 6.3x0.8</b>

### Material

Component	Brass
Surface	pure tin-plated
Insulationmaterial / Colour	PVC / red

### Technical Details


Net weight kg/1000	1.092
Conductor cross-section	0.50 – 1.50mm <sup>2</sup> / AWG 22 – 16
Temperatur resistance	up to 75°C (300V max.)
Maximum electrical rating AWG22	3A
Maximum electrical rating AWG20	4A
Maximum electrical rating AWG18	7A
Maximum electrical rating AWG16	10A

### Marking

Approved UL	E235796
UL Standard / Flammability class	UL94 / V-0

### Dimensions

L [mm]	22.50
A [mm]	10.50
D [mm]	1.70

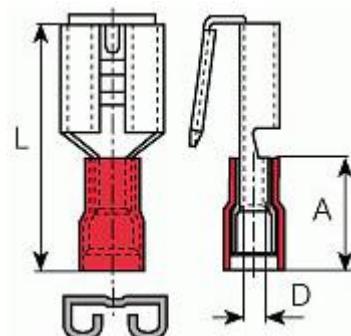

© 2022 | Vogt AG Verbindungstechnik

The general conditions of sale of Vogt AG apply to this product. See [www.vogt.ch/downloads](http://www.vogt.ch/downloads).

This data sheet is regularly revised but is not subject to any change service.

This article is a freely available article according to the above specification. The availability of certificates according to EN 10204, others acceptance test certificates or material compliance and customer-specific part submission warrant, are to be requested by the customer and, if available, can be obtained for a fee.

You can find more information on the free available product conformities at [www.vogt.ch/downloads](http://www.vogt.ch/downloads).

Form checked and approved special field: 17.02.2022 haatob

PDS\_3925s\_EN\_V1.docx

Form created: 17.02.2022 haatob

Content created: 19.08.25 karlea / Version: 01

Page 1 / 1

PM-FO-03 / Version: 00