




Cat.6 UTP Patch Cable

Cat. 6 **1000Mbps** Ethernet Cable

Home/engineering cabling

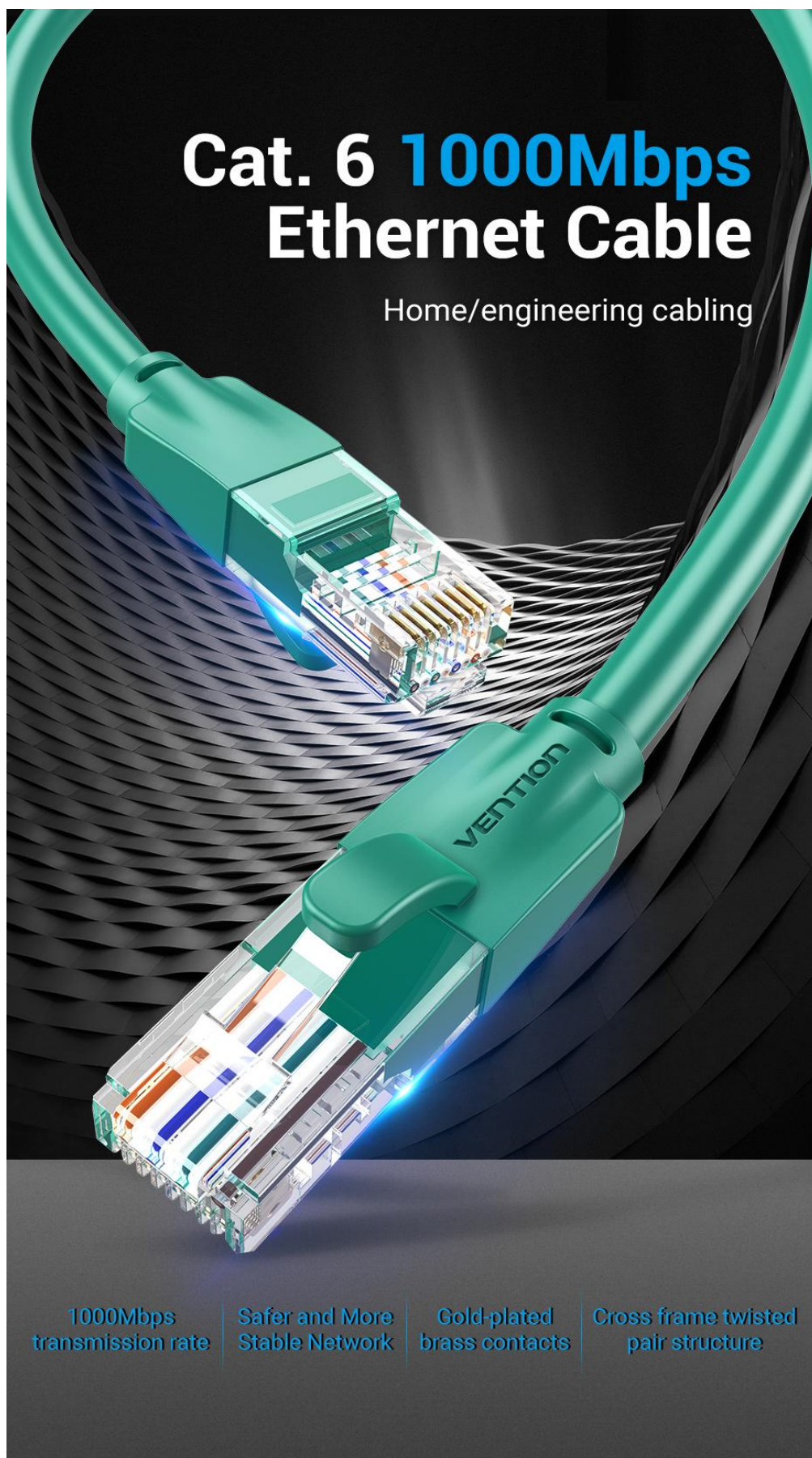

1000Mbps
transmission rate

Safer and More
Stable Network

Gold-plated
brass contacts

Cross frame twisted
pair structure

Universal Compatibility

//For all devices with RJ45 interface//



Desktop



Laptop



Router



Switch



TV




TV box



Digital printer

.....

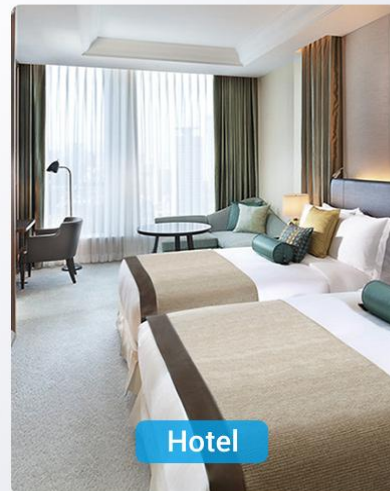

Safer and More Stable Network

Twisted pair structure, reduce interference



Gigabit Transmission

1000Mbps
transfer rate

1000Mbps

Note: All data are from Vention Lab

Stable Streaming

Watch TV shows online
with smooth connection



Smoother Game

Never miss one critical
moment in game




Four Upgrades

Upgrade 1

Cross Frame Structure

Isolated 4 pairs of double twisted conductors
stable and anti-interference

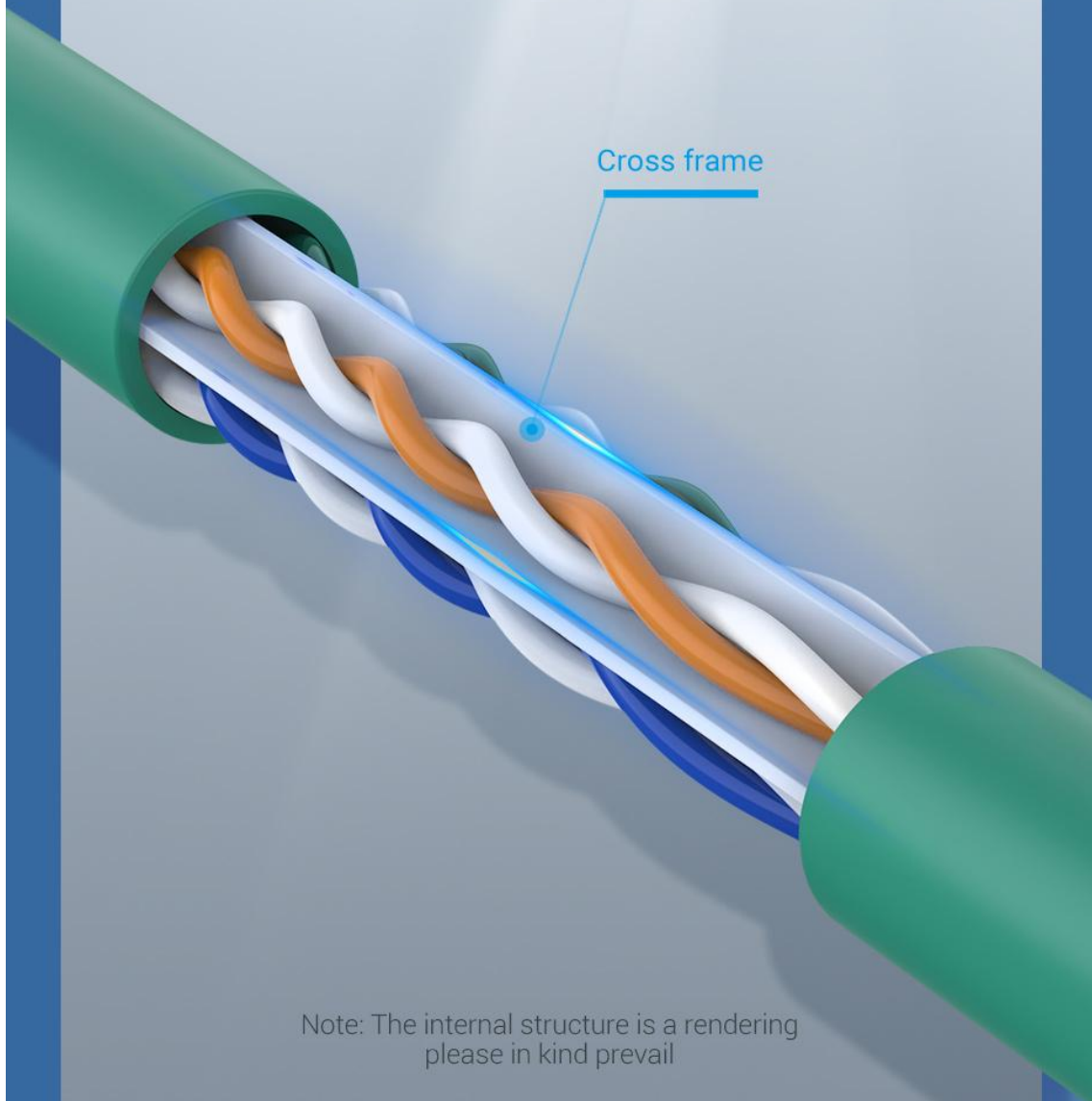


Note: The internal structure is a rendering
please in kind prevail

Upgrade 3

Gold-plated Brass Contacts

Significantly lift
transmission speed

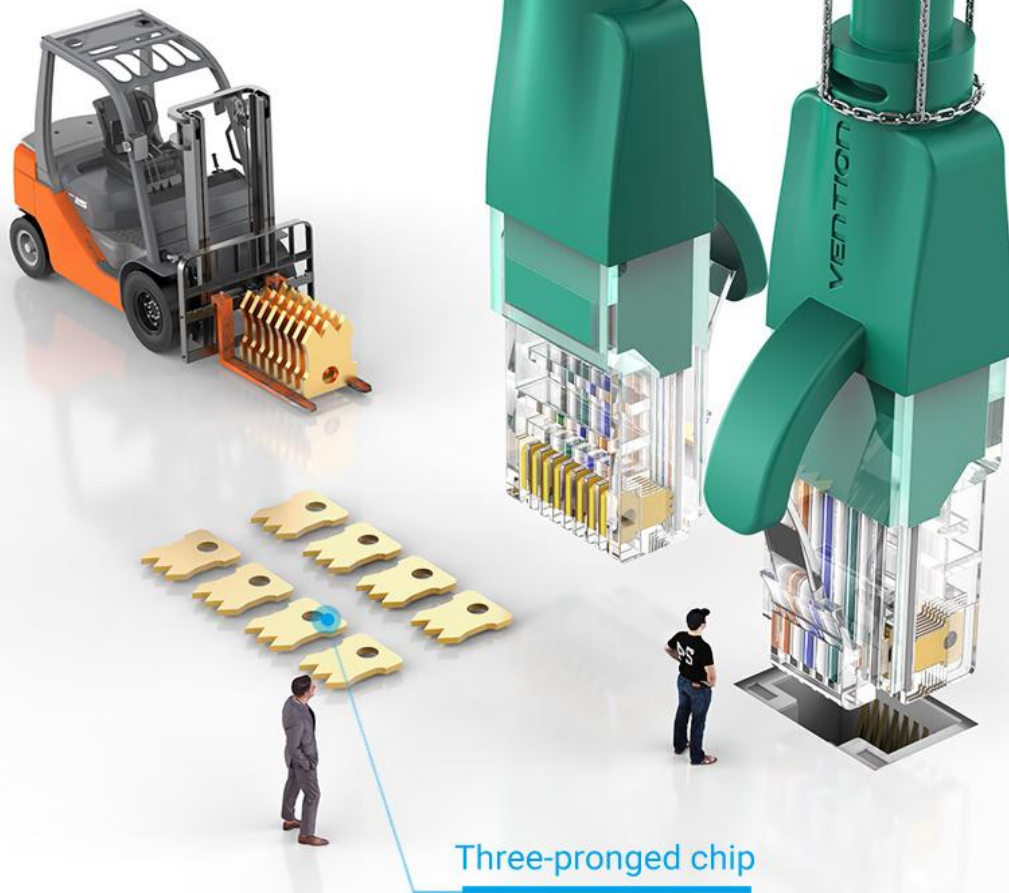

Note: The internal structure is a rendering
please in kind prevail

Upgrade 2

Bold Conductor

26AWG 8-core conductors
with twisted design



250MHz



1000Mbps

Note: The internal structure is a rendering
please in kind prevail

Upgrade 4

PVC Jacket



Wear-resistant

Anti-stretch

Water-proof

Product Parameters

Brand: Vention

Name: Cat.6 UTP Patch Cable

Model: IBEG

Color: Green

Interface: RJ45

Contact Chip Technics: Three-pronged Chip/Gold-plated Brass

Cross frame: Yes

Transmission Standard: Cat.6

Transmission Speed: 1000Mbps

Transfer Bandwidth: 250MHz

Conductor: Copper Clad Aluminum

Shell: PC

Jacket: PVC

Shielding: UTP

AWG: 26AWG

OD: 5.5mm

Length: 1/2m

Warranty: 1 Year

Packing: PE Bag



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.



Note: Packing difference exists for different meters or batches.
The photo is for reference only

Length	Art.No.	EAN Code
1m	IBEGF	6922794752191
2m	IBEGH	6922794752207



Package Contents

Cat.6 UTP Patch Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30
Carton Qty	200pcs(1m), 120pcs(2m)
Carton Weight	7kgs
Package	PE Bag