

DIGITUS® Modular Patch Panel, 24-port staggered

DN-91412

EAN 4016032295105



Modular Patch Panel, shielded, 24-port blank, 1U, rack mount, staggered, bl RAL 9005

The staggered modular 24-port Patch Panels from DIGITUS® are with the 1.5 mm cold rolled c-steel perfect suitable for 483 mm (19") rack mounting. Due to the staggered array of the keystone modules a better attenuation ratio is reached between surrounding transmission channels. They are available in the colors grey (RAL 7035) and black (RAL 9005).

- Layout Keystone Entry: Staggered
- Area of application: 483 mm (19") cabinet
- Norms: ISO/IEC 11801 3rd Ed., EN 50173-1, EIA/TIA 568-C
- General properties:
- Suitable for 483 mm (19") cabinet mounting
- Suitable for shielded Digitus® Keystone Modules and Couplers
- Central ground connection

- Technical properties:
- Housing material: 1.5 mm SPCC cold rolled stell sheet, powder-coated
- Material standard: EN 10 130(1991), BS 1449, NFA 36/401, DIN 1623, UNI 5866, UNE 36-086, SIS, JIS G 3141, ASTM, SAE, NFA 36/401
- Grounding bar material: Galvanized steel
- Physical properties:
- Operation temperature: -20° C to +70 °C (ISO/IEC 11801, EN 50173-1, ANSI/TIA/EIA 568 C)
- Colour: Black RAL9005


Attributes

- Color: black, RAL 9005
- Ports: 24
- Units: 1

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	15	13.19	56.00	40.00	30.00	67,200.00
Packaging Unit Inside	1	0.88	5.00	54.00	15.00	4,050.00
Packaging Unit Single	1	0.88	5.00	54.00	15.00	4,050.00
Net single without Packaging	1	0.78	5.00	54.00	15.00	4,050.00

More images:

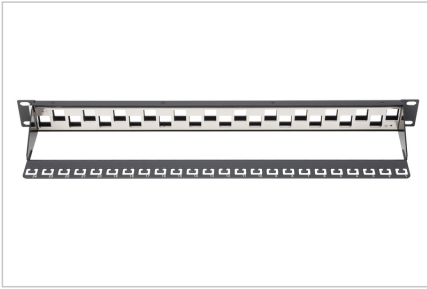

Safety notes

- Protect product from moisture
- Avoid antistatic charging when installing the product
- Observe the specifications of the raw cable manufacturer during installation

EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH
Auf dem Schöffel 3
Lüdenscheid, Germany
<https://www.assmann.com>
info@assmann.com