

19" Keystone Patch Panel 48 port with strain reliefs 2U black

Description


This patch panel by Delock can be mounted in a 19" cabinet. With its standardized dimensions, it is suitable for easy snap-in mounting of 48 Keystone modules.

Cable fixing for optimal cable management

On the back of the patch panel, the cables can be fixed with cable ties to enable clear and orderly cable routing.

Please Note

Due to the design only keystone modules up to max. 17.7 mm width can be used.

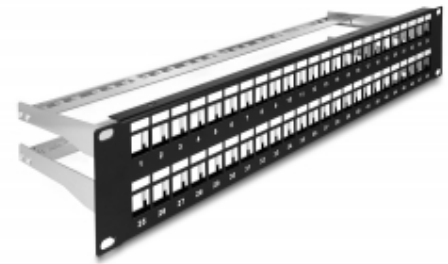

Item no. 66878

EAN: 4043619668786

Country of origin: China

Package: Box


Technical details

- For mounting in 19" network cabinet, 2U
- 48 Keystone ports 19.2 x 14.9 mm
- With labelling field
- Material: metal
- Colour: black
- Dimensions (LxWxH): ca. 482 x 151 x 88 mm

Package content

- 19" patch panel
- 48 x cable tie
- 4 x screw
- Ground wire

Images

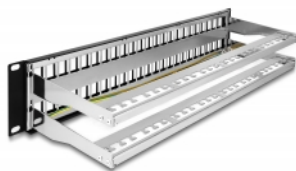

General

Mounting type:	10 in
----------------	-------

Physical characteristics

Material:	metal
Length:	482 mm
Width:	151 mm
Height:	88 mm
Colour:	black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

