


ESD PU STOOL

Catalog number: RS-K5ESD-C

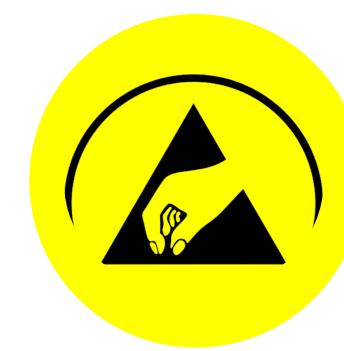

rtwork[®]
work equipment

AVAILABLE MODELS (by seat height range)



RS-K5ESD-A

Seat adjustment range:
430–555 mm

RS-K5ESD-B

Seat adjustment range:
510–695 mm

RS-K5ESD-C

Seat adjustment range:
560–810 mm

ESD PU STOOL

Catalog number: RS-K5ESD-C



*dimensions shown in mm

Model	Height adjustment range [mm]	Total height [mm]	Total width [mm]	Seat dimensions [mm]	Ground resistance (Ohm)	Load capacity [kg]	Weight [kg]
RS-K5ESD-C	560 – 810	560 – 810	700	345	$10^6 – 10^8$	120	7,7

FUNCTIONS OF ADJUSTMENT

Seat height adjustment



MATERIALS

Material shade in reality may slightly differ from that presented in the catalog.

Comfort of use: Soft polyurethane seat with height adjustment ensures ergonomic comfort during work.

Safety: Antistatic properties compliant with ESD standards effectively protect against electrostatic discharge.

Durability: Chrome-plated steel base and dirt-resistant polyurethane guarantee long-term use in demanding environments.

Application: Ideal for laboratories, production lines, and technical workspaces. Used in electronics, automotive, medical, pharmaceutical, and industrial sectors.

Chair compliant with standards:
ANSI/ESD S.20.20.2014, PN-EN 1335-1:2004, PN-EN 1335-2:2009, PN-EN 1335-3:2009, PN-EN 1022:2007, PN-EN 61340-5-1:2024



ACCESSORIES:

