




DIN 84 A

~ISO 1207

4.8

Norme abrogée

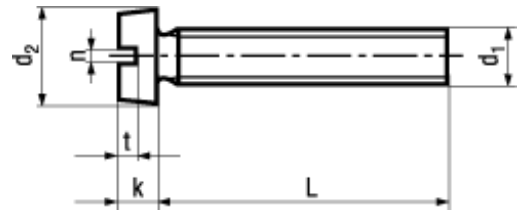

BN 332

Vis à tête cylindrique

à fente

Acier 4.8

zingué-jaune

- ~UNI 6107
- ~ČSN 021131

 [3D Cadenas](#)
 Toutes les longueurs avec filetage ~ sous tête

Article#	d ₁	d ₂	k max.	n	t min.	L
3056139	M2	3,8	1,3	0,5	0,6	2
1125109						3
1125117						4
1125125						5
1125133						6
1125141						8
1125168						10
1125176						12
1125192						16
1125214						20
1125230	M2,5	4,5	1,6	0,6	0,7	4
1125249						5
1125257						6
1125265						8
1125273						10
1125281						12
1125303						(14)
1125311						16
1125338						(18)
1125346						20
1125362						25
1125540	M3	5,5	2	0,8	0,85	4
1125559						5
1125567						6

Article#	d ₁	d ₂	k max.	n	t min.	L
1125583	M3	5,5	2	0,8	0,85	8
1125591						10
1125605						12
1125613						(14)
1125621						16
1125648						(18)
1125656						20
1125664						(22)
1125672						25
1125699						30
1125702						35
1125710						40
8271305						45
8130574						50
1125729	(M3,5)	6	2,4	1	1	5
1125737						6
1125745						8
1125753						10
1125761						12
1125796						16
1125818						(18)
1125834	M4	7	2,6	1,2	1,1	4
1125842						5
1125850						6
1125869						8
1125877						10
1125885						12
1125893						(14)
1125907						16
1125915						(18)
1125923						20
1125958						25
1125974						30
1125982						35
1125990						40
8130582						45
8067988						50
8279098						(55)
1126016	M5	8,5	3,3	1,2	1,3	6
1126024						8
1126032						10

Article#	d ₁	d ₂	k max.	n	t min.	L
1126040	M5	8,5	3,3	1,2	1,3	12
1126067						16
1126075						(18)
1126083						20
1126105						25
1126121						30
1126148						35
1126156						40
1126172						50
1126237	M6	10	3,9	1,6	1,6	10
1126245						12
1126253						(14)
1126261						16
1126296						20
1126326						25
1126342						30
1126350						35
1126369						40
1126377						45
1126385						50
1126393						(55)
1126407						60