


|                        |                                                                                                                                                                                                                                                                                                                                                                                                                            |
|------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| article#               | <b>243711-srw</b>                                                                                                                                                                                                                                                                                                                                                                                                          |
| article description    | <b>3-way connector Taurus2 rubber cap with band fb DW IP54 red</b>                                                                                                                                                                                                                                                                                                                                                         |
| description long       | 3-way connector Taurus2 rubber with cap<br>color housing/terminal-cover: black/red<br>contact carrier: polyamide<br>ready wired on 3-pole terminal block (PH1)<br>earthing system: French/Belgian (type E - with earth pin) and sealing bulge<br>contacts: nickel plated<br>250V~ / 16A / 2P+E<br>internal strain relief with cable clamp and bend<br>protection sleeve<br>for serve conditions<br>protection rating: IP54 |
| GTIN (EAN)             | 9003399619519                                                                                                                                                                                                                                                                                                                                                                                                              |
| country of origin      | AT                                                                                                                                                                                                                                                                                                                                                                                                                         |
| customs number         | 85366990                                                                                                                                                                                                                                                                                                                                                                                                                   |
| net weight             | 0.357 kg                                                                                                                                                                                                                                                                                                                                                                                                                   |
| packaging quantity     | 5                                                                                                                                                                                                                                                                                                                                                                                                                          |
| minimum order quantity | 5                                                                                                                                                                                                                                                                                                                                                                                                                          |

|                                       |                  |
|---------------------------------------|------------------|
| ETIM 9.0                              | EC001327         |
| Model                                 | Earthing pin     |
| Material                              | Rubber           |
| For heavy conditions according to VDE | True             |
| Degree of protection (IP)             | IP54             |
| Insert direction                      | Straight         |
| Connection system                     | Screwed terminal |
| Suitable for protective contact pin   | True             |
| Colour                                | Red              |
| Number of poles                       | 3                |
| Nominal voltage                       | 250 V            |
| Nominal current                       | 16 A             |

|                     |                       |
|---------------------|-----------------------|
| K (cable Ø)         | 6-13 mm               |
| wire flexible       | 1-2,5 mm <sup>2</sup> |
| contact screws      | 50 Ncm                |
| housing screws      | 160 Ncm               |
| strain relief       | 80 Ncm                |
| dismantling length  | 30 mm                 |
| stripping length    | 7 mm                  |
| ambient temperature | -25 – 40 °C           |

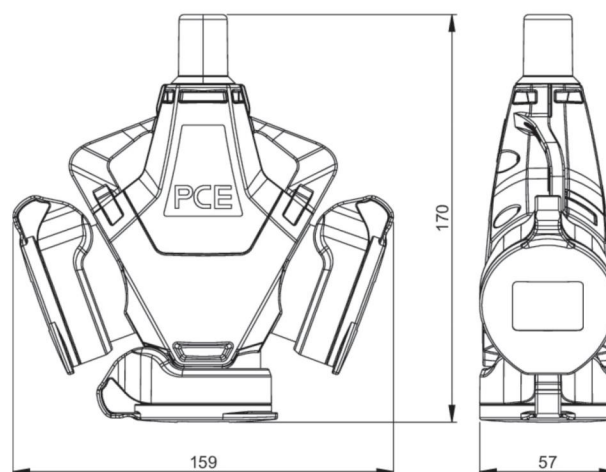

<https://www.pcelectric.at/shop/en/?func=detail&artnr=243711-srw>