


Hex socket head cap screws fully threaded

BN 31101

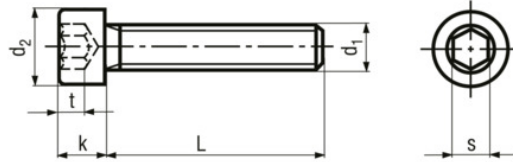

Standard	DIN 912 (Standard withdrawn), ISO 4762, ~UNI 5931, ~ČSN 021143
Headform	Cylindrical
Drive	Hexagon socket
Thread	fully threaded
Material	Stainless steel
Material type	A4
Property class	80

Article no.	d1	L	d2	s	t min.
5403297	M5	8	8,5	4	2,5
5403298	M5	10	8,5	4	2,5
5403299	M5	12	8,5	4	2,5
5807970	M5	14	8,5	4	2,5
5403300	M5	16	8,5	4	2,5
5403301	M5	20	8,5	4	2,5
5807980	M5	22	8,5	4	2,5
5403302	M5	25	8,5	4	2,5
5403309	M6	8	10	5	3
5403310	M6	10	10	5	3
5403311	M6	12	10	5	3
5808010	M6	14	10	5	3
5403312	M6	16	10	5	3
5403313	M6	20	10	5	3
5403314	M6	25	10	5	3
5403315	M6	30	10	5	3

Article no.	d1	L	d2	s	t min.
5403325	M8	12	13	6	4
5808030	M8	14	13	6	4
5403326	M8	16	13	6	4
5403327	M8	20	13	6	4
5808040	M8	22	13	6	4
5403328	M8	25	13	6	4
5400291	M8	30	13	6	4
5403329	M8	35	13	6	4
5403335	M10	16	16	8	5
5403336	M10	20	16	8	5
5403337	M10	25	16	8	5
5400295	M10	30	16	8	5
5403338	M10	35	16	8	5
5400296	M10	40	16	8	5
5403344	M12	20	18	10	6
5403345	M12	25	18	10	6
5403346	M12	30	18	10	6
5403347	M12	35	18	10	6
5400300	M12	40	18	10	6
5403348	M12	45	18	10	6
5400301	M12	50	18	10	6
5808060	M16	30	24	14	8
5808070	M16	35	24	14	8
5808080	M16	40	24	14	8
5808090	M16	45	24	14	8
5808100	M16	50	24	14	8
5808110	M16	55	24	14	8
5808120	M16	60	24	14	8
5808200	M20	40	30	17	10
5808210	M20	45	30	17	10
5808220	M20	50	30	17	10
5808230	M20	55	30	17	10
5808240	M20	60	30	17	10
5808250	M20	70	30	17	10
5808310	M24	50	36	19	12
5808320	M24	60	36	19	12
5808330	M24	70	36	19	12
5808340	M24	80	36	19	12