

Delock WLAN 802.11 b/g/n Antenna RP-SMA 4 dBi Omnidirectional Flexible Joint ULA100 1 m With Magnetic Stand

Description

This Wireless LAN antenna can be connected to your device with RP-SMA interface, in order to send and receive signals. Due to the three tilt stages of the flexible antenna and the magnetic stand you can place the antenna individually.



Item no. 88413

EAN: 4043619884131

Country of origin: Taiwan,
Republic of China

Package: Blister



Technical details

- Omni directional antenna
- RP-SMA screw interface
- With flexible joint – three step
- Compatible to IEEE 802.11n and IEEE 802.11b/g, 802.3, 802.3u, Bluetooth
- Frequency range: 2.4 GHz - 2.5 GHz
- Gain: 4 dBi
- Impedance: 50 Ohm
- Operating temperature: -10°C to +55°C
- 1 m ULA100 connecting cable
- Stand with magnetic and rubberized bottom side
- Dimension: with flexible joint 200 mm, without flexible joint 165 mm

Package content

- WLAN antenna

Images

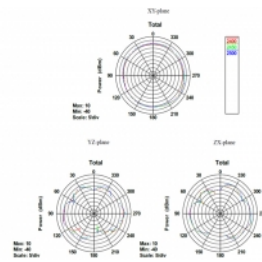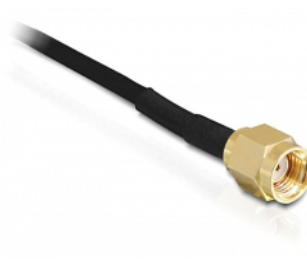

General

Mounting type:	magnetic
----------------	----------

Interface

Connector:	1 x RP-SMA plug
------------	-----------------

Technical characteristics

Frequency range:	2400 - 2500 MHz
Antenna gain:	4 dBi
Impedance:	50 Ω
Operating temperature:	-10 °C ~ 55 °C
VSWR:	< 2.0

Physical characteristics

Antenna type:	omnidirectional
Cable length incl. connectors:	1 m
Length with tilt joint:	200 mm
Length without tilt joint:	165 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

