


Description	: Alkaline Zinc - Manganese dioxide mercury-free button cell
Chemical system	: Zinc-Manganese Dioxide
Nominal voltage	: 1.5Volts
Nominal capacity	: 110mAh
Dimensions	: Ø11.60mm x 5.4mm
Average weight	: 1.7 grams
Operation temperature	: 0°C - 45°C
Storage temperature	: 10°C ~25°C
Shelf life	: 3 years at room temperature

Model no.: **A76F / A76FX**

Ultra

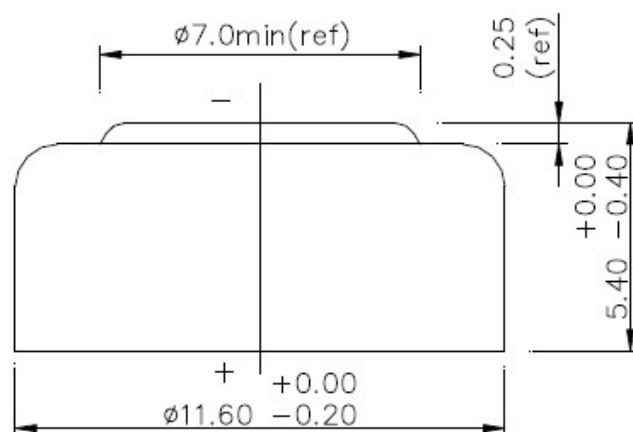

Unit: mm


Cross References:

IEC	JIS	ANSI	Varta
LR44	A13	1166A	LR44

Discharge Characteristics

Voltage (V)

IEC Standard service output test (Load:
6.8KOhm, end voltage 1.2V)

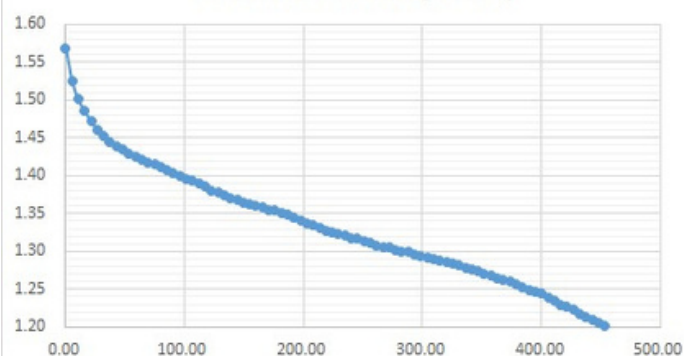

Discharge hour (hr)

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.