

ARCA 505021T No MP

FIBOX
Enclosing innovations



Sample image

Order symbol : ARCA 505021T No MP

Product nr : 8121032N

Description : Cabinet, PC



Remarks : Transparent cover, 2-point locking, without mountingplate

EAN : 6418074317995

El. number :

- Finland : 3425147
- Denmark : 8212056394
- Sweden : 2507067

Including : Cabinet base, door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

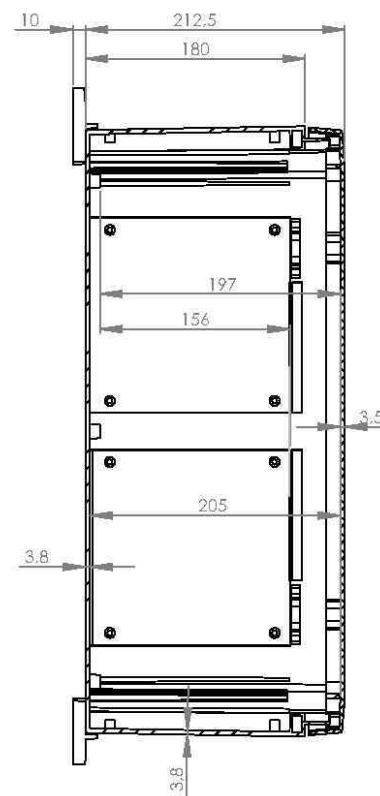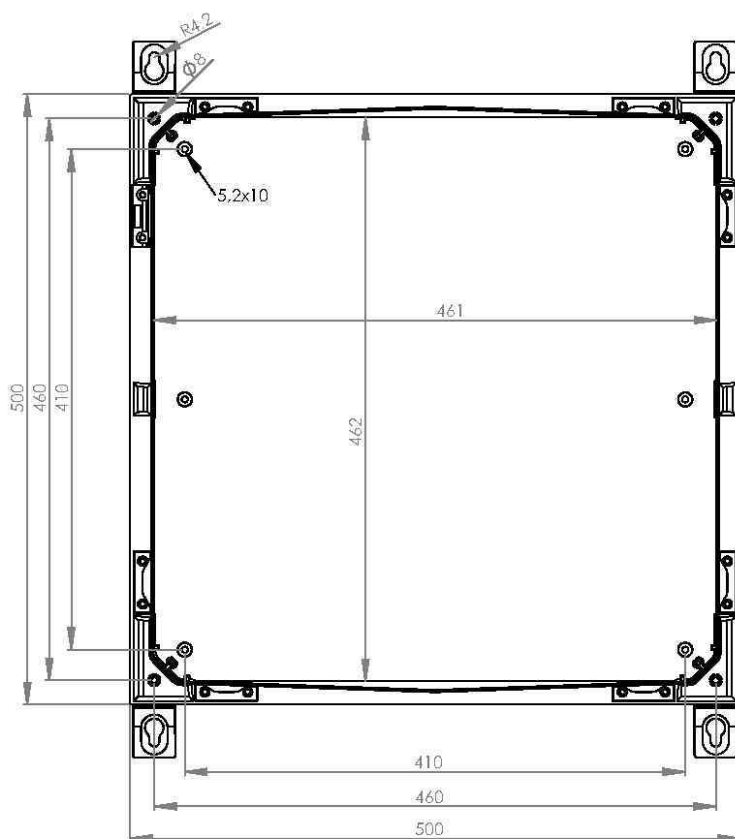

Dimensions :

Height	Width	Depth
mm :	500	500
inch :	19.69	19.69

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Smoked grey
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Accessories :

MPMP ARCA 5050	Mounting plate multiperforated (450x450x2 mm - Ø3.6 mm) (450 x 450 x 1.5)
MPX ARCA 5050	Mounting plate (450x450 mm) (450 x 450 x 5)
MPS ARCA 5050	Mounting plate (450x450x2 mm) (450 x 450 x 2)
DRS ARCA 505021	DIN rail frame set (480 x 480 x 30)
RCS ARCA 5050	Rain canopy set for size 5050 (30 x 500 x 20)
IDS ARCA 5050	Inner door set (480 x 480 x 30)
MPP ARCA 5050	Mounting plate perforated (450x450x2 mm - 26x11 mm) (450 x 450 x 2)
PMK ARCA 50	PoleMounting kit, for pole Ø100-300mm (485 x 385 x 35)

Ratings :

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK09;
electrical_insulation :	Totally insulated

Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960C
UL Type	1, 4, 4X, 12, 13

Certificates :
Certificate FI 40467