


DIGITUS® Modular High Density Patch Panel, shielded

DN-91422

EAN 4016032343295

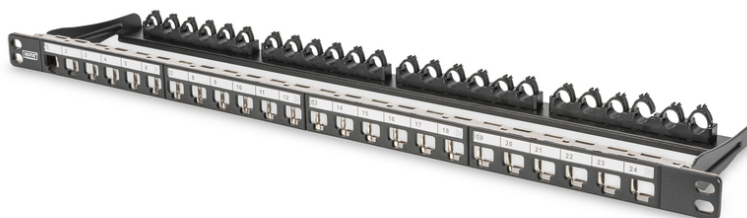

Modular Patch Panel, shielded, 24-port label field, 0.5U, rack mount, black RAL 9005

The DIGITUS® 24-port 0.5U patch panel offers you a high packing density. As the panel is only 0.5U high, 48 ports (2 panels with 24 ports each) can be installed on 1U.

- Keystone mount design: 2-row
- Application areas: 483 mm (19") distribution cabinet
- Standards: ISO/IEC 11801 3rd Ed., EN 50173-1, EIA/TIA 568-C
- General properties:
- Suitable for 483 mm (19") rack mounting
- Suitable for shielded Digitus® Keystone modules and connectors
- Central earthing connection
- Plastic labeling field
- Technical features:

- Housing material: 1.5 mm SPCC cold-rolled sheet steel, powder-coated
- Material standard: EN 10 130(1991), BS 1449, NFA 36/401, DIN 1623, UNI 5866, UNE 36-086, SIS, JIS G 3141, ASTM, SAE, NFA 36/401
- Material earthing bar: galvanized steel
- Physical properties:
- Operating temperature: -20° C to +70 °C (ISO/IEC 11801, EN 50173-1, ANSI/TIA/EIA 568 C)
- Color: Black RAL9005
- HE: 0.5



Attributes

- Color: black, RAL 9005
- Ports: 24
- Units: 0

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	10	6.30	55.00	38.00	18.00	37,620.00
Packaging Unit Inside	1	0.63	3.00	53.00	18.00	2,862.00
Packaging Unit Single	1	0.63	3.00	53.00	18.00	2,862.00
Net single without Packaging	1	0.54	3.00	53.00	18.00	2,862.00

More images:

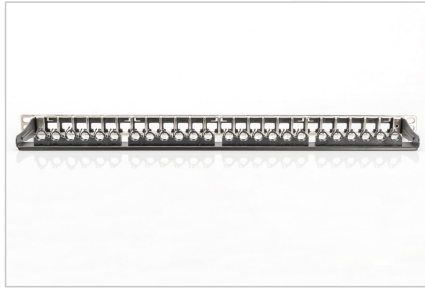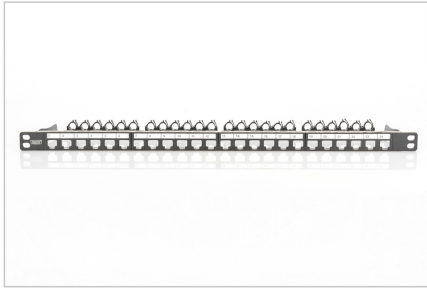

Safety notes

- Protect product from moisture
- Avoid antistatic charging when installing the product
- Observe the specifications of the raw cable manufacturer during installation

EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH
Auf dem Schöffel 3
Lüdenscheid, Germany
<https://www.assmann.com>
info@assmann.com