

USB Retractable Cable Type-A to USB-C™ black / red

Description

This practical retractable cable by Delock can be connected to a PC or laptop with USB-A port and can be used to transfer data and charge the connected device.

Useful companion

Due to its small size, the cable is a practical companion on the go and always at hand. A knotting of the cables is avoided by its winding mechanism.

Flexible

The cable can be pulled out in five stages and thus offers different cable lengths, depending on requirements.



Item no. 85819

EAN: 4043619858194

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 1 x USB 2.0 Type-A male >
 - 1 x USB 2.0 Typ-C Stecker
- Maximum output current: 2.1 A
- Voltage: max. 5 V
- Cable gauge:
 - 28 AWG data line
 - 24 AWG power line
- Flat cable
- Connector with metal housing
- Colour: black / red
- Dimensions of housing (DxH): ca. 5.6 x 2.3 cm
- Length incl. connectors: ca. 92 cm (total incl. housing)
 - USB-A Host-cable ca. 46 cm
 - USB Type-C™ cable ca. 46 cm


System requirements

- PC or laptop with a free USB Type-A port

Package content

- Cable

Images

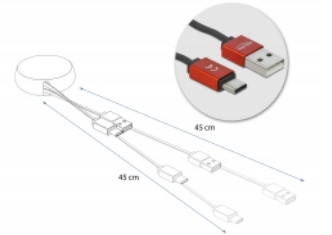

General

Specification:	USB 2.0
----------------	---------

Interface

Connector 1:	1 x USB 2.0 Type-A male
Connector 2:	1 x USB 2.0 Type-CTM male

Technical characteristics

Maximum current:	2.1 A
Voltage:	5 V

Physical characteristics

Housing material:	metal
Cable length incl. connectors:	92 cm
Cable gauge:	28 AWG data line 24 AWG power line
Colour:	red black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

