

Keystone Module RJ45 jack Cat.6A STP 4 pieces

Description

This module by Delock can be used to connect twisted pair cable to an RJ45 jack. With its standardised dimensions it can be used for easy snap-in mounting in e.g. a Keystone patch panel, face plate or surface-mount box.



Item no. 86050

EAN: 4043619860500

Country of origin: China

Package: Zip poly bag


Technical details

- Connectors:
1 x RJ45 jack (8P/8C)
1 x LSA (toolfree)
- Cat.6A specification
- Shielded (STP)
- Material: zinc diecast
- TIA-568A/B pinout
- For solid or stranded wire up to 0.573 mm (23 - 26 AWG)
- For cable diameter from 5.5 - 9.0 mm
- For Keystone ports with 19.2 x 14.9 mm
- Operating temperature: -10 °C ~ 60 °C
- Dimensions (LxWxH): ca. 38.6 x 16.3 x 23.0 mm

Package content

- 4 x Keystone module
- 4 x cable manager
- 4 x cable tie

Images

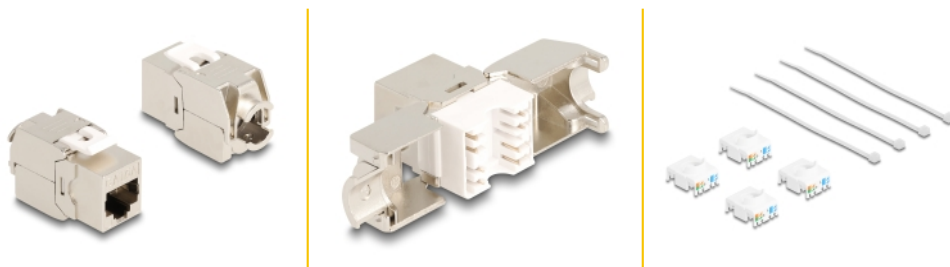

General

Suitable for conductor gauge:	22 - 24 AWG
Mounting type:	Keystone module
Specification:	Cat. 6A

Interface

External:	1 x RJ45 jack
Internal:	1 x LSA block

Physical characteristics

Housing material:	zinc die cast
Shielding:	shielded
Length:	38.6 mm
Width:	16.3 mm
Height:	23 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

