

# USB Type-C™ Splitter (DP Alt Mode) to 2 x DisplayPort MST / VXP

## Description

This splitter by Delock is suitable for the connection of two DisplayPort monitors to a computer with **USB-C™** interface and **DisplayPort alternate mode** support. Two monitors can be operated simultaneously at the outputs.



### Multi-Stream Transport (MST)

The product is a Multi-Stream Transport (MST) hub and supports the **extended desktop** configuration of DisplayPort. In **Windows**, the connected monitors are controlled individually, and can be combined into one large display.

**Item no. 87754**

EAN: 4043619877546

Country of origin: China

Package: Retail Box

### VXP technology

If the connected computer does not support MST, the **ViewXpand™** technology is activated. Multiple monitors with the same resolution are recognized as **one single large display**, allowing desktop display on multiple external monitors, e.g. in **Mac OS**. The maximum resolution is **3840 x 1080 @ 60 Hz**.

### Please Note

Only one additional external monitor can be connected to MacBook devices with M1 chipset.

## Technical details

- Connectors:  
Input: 1 x USB Type-C™ male  
Output: 2 x DisplayPort female
- Chipset: VMM5220
- DisplayPort 1.4 specification
- Supports Display Stream Compression 1.2 (DSC)
- Supports HDR
- Supports HDCP 1.4 and 2.2
- Maximum resolution (depending on the system and the connected hardware):  
DisplayPort 1.1 or 1.2 Single-Stream Transport (SST):  
up to 3840 x 1080 @ 60 Hz (VXP)  
DisplayPort 1.2 Multi-Stream Transport (MST):  
up to 2560 x 1440 @ 60 Hz or 3840 x 2160 @ 30 Hz (mirror or extended)

DisplayPort 1.4 Multi-Stream Transport (MST):  
up to 3840 x 2160 @ 60 Hz (mirror or extended)

- Active converter, Single- / Multi-Stream Transport Hub (SST / MST)
- Transmission of audio and video signals
- USB bus powered
- Colour: black
- Cable length incl. connectors: ca. 20 cm
- Dimensions (LxWxH): ca. 61 x 49 x 12 mm


## System requirements

- Windows 10/11
- Mac OS 10.14.4 or above
- PC or laptop with a free USB Type-C™ port and DisplayPort alternate mode or
- PC or laptop with a free Thunderbolt™ 3 port

## Package content

- USB-C™ Splitter (DP Alt Mode)
- User manual

## Images

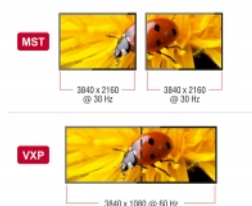

## General

|                             |                                                                                 |
|-----------------------------|---------------------------------------------------------------------------------|
| Specification:              | DisplayPort 1.4                                                                 |
| Supported operating system: | Mac OS 10.14.5 or above<br>Windows 10 32-Bit<br>Windows 10 64-Bit<br>Windows 11 |

## Interface

|         |                        |
|---------|------------------------|
| Output: | 2 x DisplayPort female |
| Input:  | 1 x USB Type-C™ male   |

## Technical characteristics

|                            |                     |
|----------------------------|---------------------|
| Maximum screen resolution: | 3840 x 2160 @ 60 Hz |
|----------------------------|---------------------|

## Physical characteristics

|                                |         |
|--------------------------------|---------|
| Housing colour:                | black   |
| Housing material:              | Plastic |
| Cable length incl. connectors: | 25 cm   |
| Length:                        | 61 mm   |
| Width:                         | 49 mm   |
| Height:                        | 11 mm   |

## Manufacturer information

|             |                   |
|-------------|-------------------|
| Street      | Beeskowdamm 13/15 |
| Postal code | 14167             |
| City        | Berlin            |
| Country     | Deutschland       |
| E-Mail      | info@delock.de    |
| Website     | www.delock.de     |