

Product datasheet

## ORIGINAL - METAL BASE R5W

Original spare part



### The cost-effective original spare parts for trucks

Discover OSRAM's ORIGINAL signal lamps with metal bases - high-quality original spare parts for 24 volt lamps. Due to the wide product range, the lamps can be used for different applications: as position and parking lights, indicator, brake, fog and reversing lights as well as number plate and side position lights.

# Product datasheet

## Technical data

### Product information

Application (Category and Product specific)	Auxiliary lamp
---	----------------

### General Product Information

Global order reference	5627
------------------------	------


### Electrical Data

Power input	7 W
Nominal voltage	24 V
Nominal wattage	5 W
Power input tolerance	±10 %
Test voltage	28.0 V

### Photometric Data

Nominal luminous flux	50 lm
Luminous flux tolerance	±20 %

### Physical Attributes & Dimensions

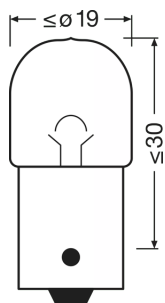

Lamp base	BA15s
Length	37.5 mm
Diameter	16.0 mm
Product weight	6.02 g

### Lifetime Data

Lifespan B3	500 hr
Lifespan Tc	1000 hr

## Product datasheet

### Capabilities

Technology	AUX
------------	-----

### Certificates & standards

ECE category	R5W
--------------	-----

### Environmental & Regulatory Information

Information according Art. 33 of EU Regulation (EC) 1907/2006 (REACH)	
Primary article identifier	4052899418882   4050300925967   4050300991405   4050300838335
Candidate list substance 1	No declarable substances contained
Declaration no. in SCIP database	No declarable substances contained

### Country specific information


Product code	METEL code	SEG number	STK number	UK Org
4050300838335	OSRA5627	8328138	4739925	-

### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300838335	ORIGINAL - METAL BASE R5W	Unpacked 1	37 mm x 16 mm x 16 mm	0.01 dm <sup>3</sup>	6.00 g
4008321095367	ORIGINAL - METAL BASE R5W	Shipping carton box 50	205 mm x 144 mm x 64 mm	1.89 dm <sup>3</sup>	416.00 g
4050300925967	ORIGINAL - METAL BASE R5W	Blister 2	95 mm x 70 mm x 18 mm	0.01 dm <sup>3</sup>	17.00 g
4008321140432	ORIGINAL - METAL BASE R5W	Shipping carton box 20	189 mm x 80 mm x 103 mm	1.56 dm <sup>3</sup>	215.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

### Download Data

File
 User instruction GPRS_Safety symbols instructions



Addon Technical Information  
Product Certificates AUX

### Application advice

For more detailed application information and graphics please see product datasheet.

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.



# OSRAM