


PoweredUSB cable male 12 V > DC 5.5 x 2.1 mm male 4 m for POS printers and terminals

Description

This PoweredUSB cable by Delock can be used to supply power to a device with DC 5.5 x 2.1 mm female port via a PC or hub with PoweredUSB 12 V port.

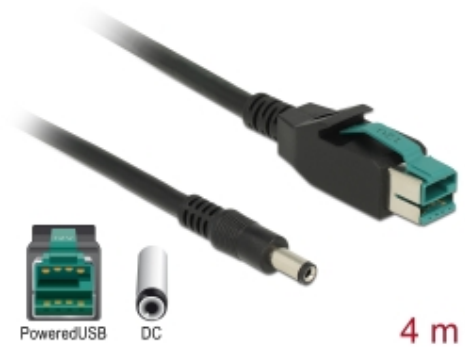

Item no. 85500

EAN: 4043619855001

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
 - 1 x PoweredUSB male 12 V >
 - 1 x DC 5.5 x 2.1 mm male
- PoweredUSB specification
- Voltage: 12 V
- Cable gauge: 24 AWG
- Cable diameter: ca. 6 mm
- Cable double shielded
- Colour: black
- Length incl. connectors (L): ca. 4 m


System requirements

- PC or hub with a free PoweredUSB 12 V female port

Package content

- PoweredUSB cable

Images

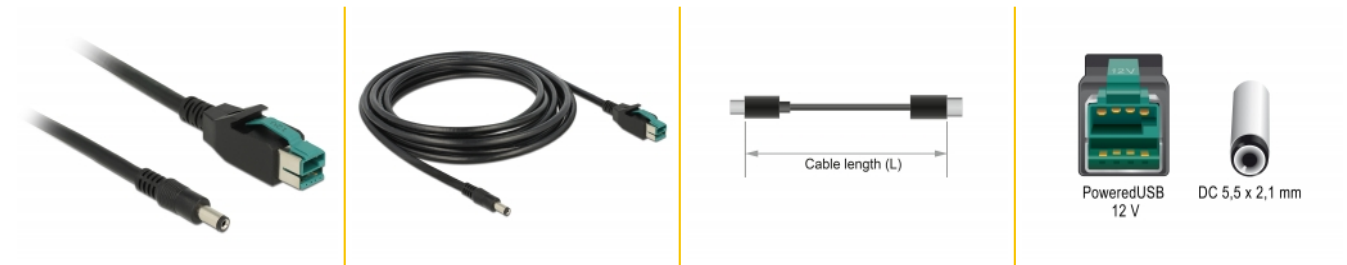

General

Specification:	PoweredUSB
----------------	------------

Interface

Connector 1:	1 x PoweredUSB male 12 V
Connector 2:	1 x DC 5.5 x 2.1 mm male

Technical characteristics

Voltage:	12 V
----------	------

Physical characteristics

Cable gauge:	24 AWG power line
Shielding:	double
Length:	4 m
Colour:	black
Cable diameter:	6 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

