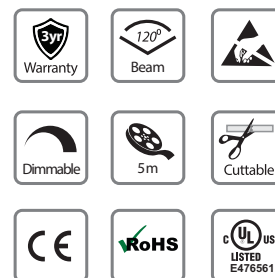


Dual White

3527 60LED



CRI Option

- 80+
- 90+

PCB Thickness

- 2oz
- 3oz
- 4oz - on request

PCB Color

- White
- Black
- Golden

Color Option



2700K - 6500K

Technical Data


Voltage	Code	Color	Watts	Lumen	Efficiency	Pitch	Width
12VDC	J60110-CCT-2in1	2700K	6	468	78	50mm	10mm
		6500K	6	480	80		
		Mix 4000K	Max. 12	960	80		
24VDC	J60210-CCT-2in1	2700K	6	468	78	100mm	10mm
		6500K	6	480	80		
		Mix 4000K	Max. 12	960	80		

The above measurements are based on IP20.


The above measurements can have a 10% tolerance.

Dimensions

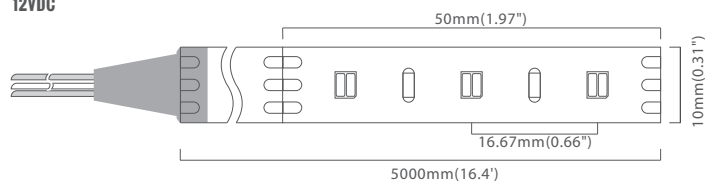12VDC










24VDC

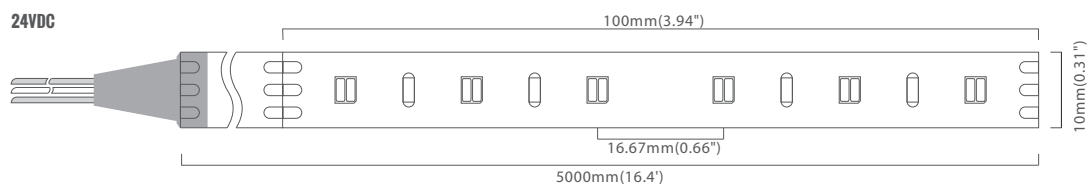

Main Features


- More options on Ra>90.
- 3527 2in1 SMD to better mixed color.
- 12V or 24V low voltage input for human safety.
- Ideal for office, residential, retail and industry lighting.

       Available Waterproof Ways

IP Rating	20	54A	54B	65A	65B	67	68
Section							
Material	none	Silicone glue on surface	PU glue on surface	Inject with Heat Shrink tube	Inject with silicone tube	Silicone extrusion	Silicone extrusion

Multi-Color LED Strip Light

Accessory |

 

HH-1616



HH-1707D



HH-1707