



BETA 1221N

Morphos screwdrivers for slotted head screws, extra-short series



Certifications and Standards



Features

Designed to reduce fatigue and ensure high torque transmission even in the most demanding applications.

CONTROL AND PRECISION

The ergonomic shape and designed index finger and thumb rests guarantee a firm grip and precise centring of the blade on the screw. Even with dirty hands or gloves, you achieve maximum directionality and safety during use.

PERFECT GRIP AND ANTI-ROLL

The embossed texture ensures a reliable grip even under the most difficult conditions. The triangular profile prevents rolling on the work surface and promotes stable and continuous use.

STRENGTH AND DURABILITY

The chrome-plated steel blade with sandblasted finish offers protection against corrosion and wear. The black phosphated tip ensures a precise fit with the screw and reduces the risk of slipping, prolonging the life of the tool.



ANTI-ROTATION

The triangular shape prevents rolling on the workbench, improving safety and stability.



PHOSPHATED TIP


The phosphated tip ensures a perfect fit with the screw, preventing damage and optimising work efficiency.



BEST-IN-CLASS PERFORMANCE

The proven Beta blades offer elasticity, hardness and wear resistance at the top of the professional screwdriver category.

Dimensions

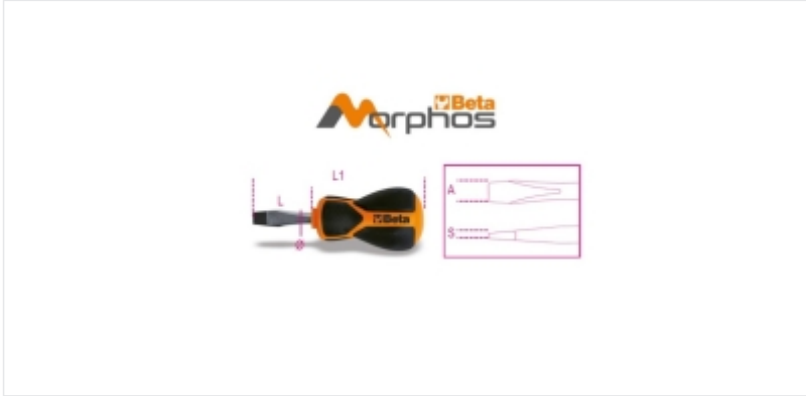

Certifications and Standards

Coded items

	Art.	SxAxL mm	L1 mm	Ø mm	g
012210103	1221N 4X30	0,8x4x30	87,5	4	34
012210106	1221N 6,5X30	1,2x6,5x30	87,5	6	43

Scan the QR Code to access the web tab
Specs, media and documentation in one click.

