


EXIOS +MZ brass blank

Item number 16Z5320050

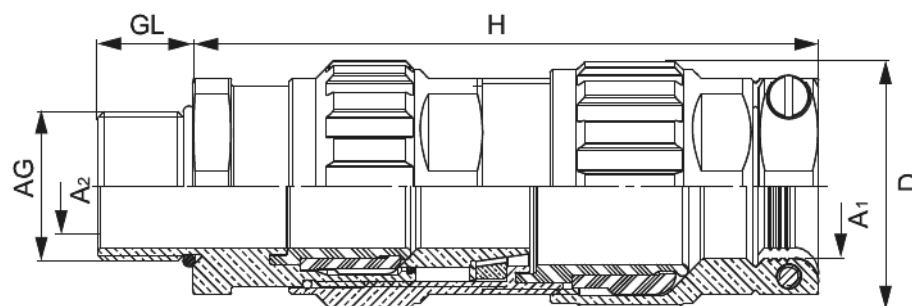

Technical data

Material	Brass
Seal	VMQ (silicone)
Material o-ring	VMQ (silicone)
Clamping insert	Polyamide 6
Armour	Metallic armour or screen
Protection class	IP 68 - 5 bar, IP 67, IP 66
Ex-protection level	Class I Div 2 Groups A,B,C,D, Class II Div 1 Groups E,F,G , II 1D Ex ta IIIC Da, II 2G Ex eb IIC Gb
Temperature range	-60°C to +105°C
Variant	Metric
External thread (AG)	M32 x 1,5
Size	32
A1	22 - 32.5 mm
A2	16.9 - 26 mm
Thread length (GL)	16 mm

EXIOS +MZ brass blank

Item number 16Z5320050

Height (H)	107 mm
Wrench size (SW1/SW2)	46/46 mm
D	52 mm
Armouring clamping ring 1	- 0,7 mm
Armouring clamping ring 2	1,3 - 2 mm
Armouring clamping ring 3 (optional)	0,7 - 1,4 mm
Tightening torque	30 Nm

EXIOS +MZ brass blank

Item number 16Z5320050

Commercial data

Packaging Unit	1
EAN code	4033878001394
Weight	0.65 kg
ETIM 7	EC000441
eCl@ss 10.1	27-14-44-34

Note:

