


JJJ Battery Co.,LTD.

MODEL No: J-AA1300H

Description: 1300 mAh SIZE Ni-MH AA




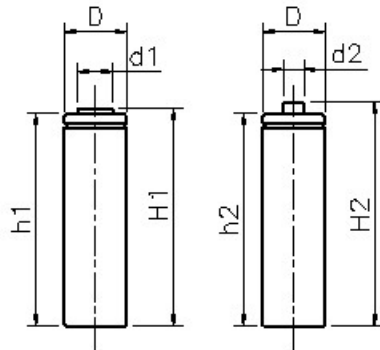


Dimensions(without Tube) (mm)

D	13.90±0.10		
d1	8.10±0.08	d2	4.75±0.08
H1	48.00±0.50	H2	49.50±0.50
h1	47.50±0.50	h2	47.50±0.50

Specification

Nominal Capacity		1300 mAh	
Nominal Voltage		1.2 V	
Charge current	Trickle	65 mA	
	Standard	130 mA	
Charge time	Trickle	48 Hrs~	
	Standard	14~16 Hrs	
Ambient Temperature	Charge	Trickle	0℃~70℃
		Standard	0℃~70℃
	Discharge		-20℃~70℃
	Storage		-20℃~55℃
Internal Impedance(m Ω) (After Charge)		≤ 26	
Weight		25 g	

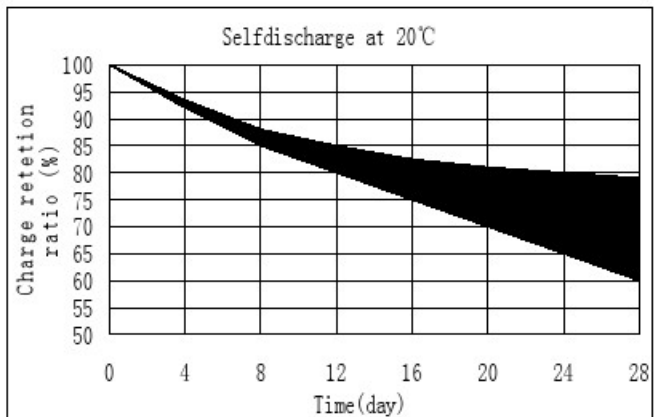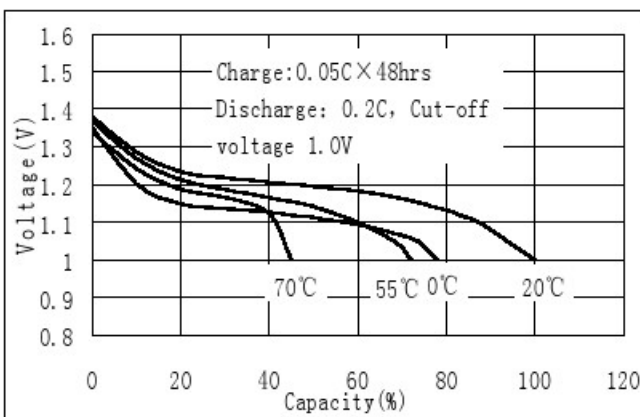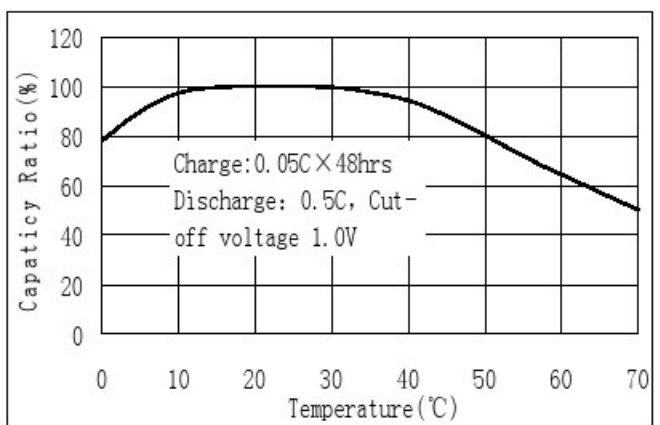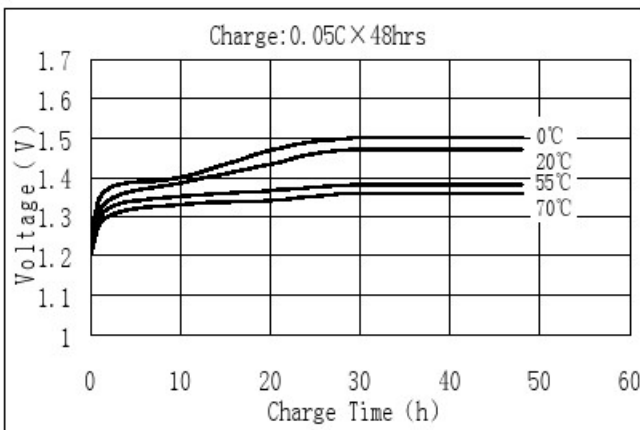

JJJ reserves the right to alter or amend the design,model and specification without prior notice.

JIANGMEN JJJ BATTERY CO.,LTD.