


BETA 96TBP-HS

Ball head offset hexagon key wrenches with high torque handles, chrome-plated, with

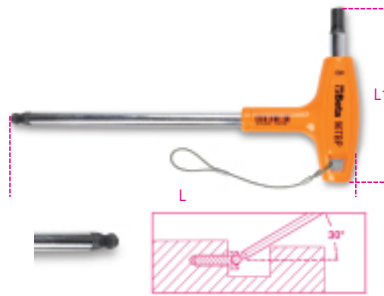

Certifications and Standards

○

Features

History and innovation: the iconic Beta 96T spanner in its spherical tip version

Ergonomics

The ergonomic handle follows the anatomical lines of the hand and allows you to work with a firm and secure grip

Application in confined spaces

The spherical tip allows working angles of up to 30°.

This allows wide use in different situations and in the most difficult spaces

Ductility

Double tightening/untightening thanks to the hexagon on the short side of the spanner and the spherical tip on the long side

H-SAFE system

The proven Beta H-SAFE system allows the tool to be used even when working at height, helping to prevent the risk of the spanner falling and minimising accidental damage to people and/or property

Certifications and Standards



Coded items

	Art.	O mm	L mm	L1 mm	Ø mm	S mm	
000964685	96TBP-HS 2,5	2,5	153	55	4	13,4	22
000964686	96TBP-HS 3	3	153	55	4	13,4	22
000964687	96TBP-HS 4	4	179	70	5	17,8	43
000964688	96TBP-HS 5	5	200	84	6	22,0	71
000964689	96TBP-HS 6	6	221	103	7	24,0	103
000964690	96TBP-HS 8	8	255	117	10	26,0	214
000964692	96TBP-HS 10	10	285	132	12	27,6	230

Scan the QR Code to access the web tab
Specs, media and documentation in one click.

