

ISM 433 MHz Antenna SMA Plug 3 dBi omnidirectional fixed black adhesive mounting

Description

This antenna by Delock allows the use of ISM 433 MHz band indoors.



Item no. 89495

EAN: 4043619894956

Country of origin: China

Package: Zip poly bag

Technical details

- Connector: SMA plug
- Frequency range: 433 MHz
- Gain: 3 dBi
- Impedance: 50 Ohm
- Polarisation linear vertical
- VSWR: 2.0
- Operating temperature: -40 °C ~85 °C
- Colour: black
- Antenna length: ca. 2 x 55 mm
- Antenna length with adhesive base: 150.2 mm
- Dimension adhesive base: ca. 40.4 x 17.0 x 8.7 mm
- Cable category: coaxial
- Cable type: RG-174
- Cable colour: black
- Cable length incl. connector: ca. 2 m


System requirements

- Device with free SMA connector

Package content

- ISM 433 MHz Antenna

Images

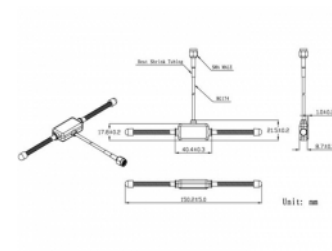

General

Mounting type:	Self adhesive
Suitable for indoor:	yes
Suitable for outdoor:	no

Interface

Connector:	1 x SMA plug
------------	--------------

Technical characteristics

Frequency range:	433 MHz
Bandwidth:	± 10 MHz
Antenna gain:	3 dBi
Impedance:	50 Ω
Operating temperature:	-40 °C ~ 85 °C
Polarisation:	linear
VSWR:	2.0

Physical characteristics

Antenna type:	dipol antenna
Housing material:	ABS
Cable category:	coaxial
Cable type:	RG-174
Cable colour:	black
Cable length incl. connectors:	2 m
Length:	2 x 55 mm
Colour:	black

Manufacturer information

Street Beeskowdamm 13/15

Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

