


- For working sheet metal

	Art.	L mm	Ø mm	S mm	D mm	g
004250010	425/1	70	4÷12	1	6	19
004250012	425/2	55	4÷12	2	6	22
004250015	425/3	85	4÷20	2	10	57
004250016	425/4	85	12÷20	1	10	79
004250017	425/5	97	20÷30	1	10	203
004250020	425/6	75	4÷30	2	10	140
004250025	425/7	97	30÷40	1	13	312
004250029	425/8	100	40÷50	1	13	514

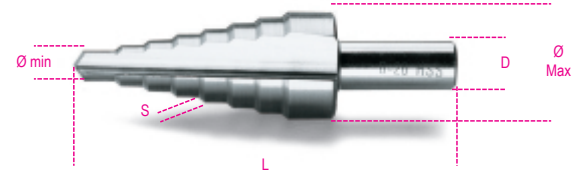

Scan the QR Code to access the web tab

Specs, media and documentation in one click.

