


RJ45 Network Cable Cat.6A S/FTP PE Outdoor 20 m black

Description

This network cable by Delock can be used to connect different networking devices, e.g. a NIC to a switch or a patch panel.

With PE (Polyethylene) cable jacket

The network cable is ideal for outdoor use and offers increased resistance to UV light, cold, heat, moisture and corrosion.

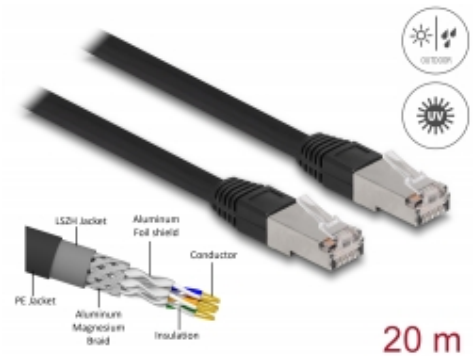

Item no. 80132

EAN: 4043619801329

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
 - 1 x RJ45 plug
 - 1 x RJ45 plug
- 1:1 connected
- Cat.6A specification
- Shielded (S/FTP)
- LSZH (halogen-free)
- Environmental temperature: -20 °C ~ 60 °C
- Cable gauge: 26 AWG
- Cable diameter: ca. 7.0 mm
- Cable jacket material: PE + LSZH
- Colour: black
- Length: ca. 20 m


System requirements

- A free RJ45 jack

Package content

- Patch cable

Images

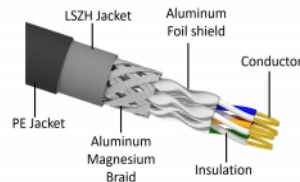

General

Specification:	Cat. 6A
Style:	both sides identical

Interface

Connector 1:	1 x RJ45 male
Connector 2:	1 x RJ45 male

Technical characteristics

Operating temperature:	-20 °C ~ 60 °C
------------------------	----------------

Physical characteristics

Cable gauge:	26 AWG
Shielding:	S/FTP
Length:	20 m
Colour:	black
Cable jacket material:	PE + LSZH

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de