

# ARCA 403015T No MP



Sample image

**Order symbol :** ARCA 403015T No MP

**Product nr :** 8121006N

**Description :** Cabinet, PC


**Remarks :** Transparent cover, 2-point locking, hinges on the long side, without mountingplate

**EAN :** 6418074317940

**El. number :**

- Finland : 3425127
- Denmark : 8212056420
- Sweden : 2507043

**Including :** Cabinet base, door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

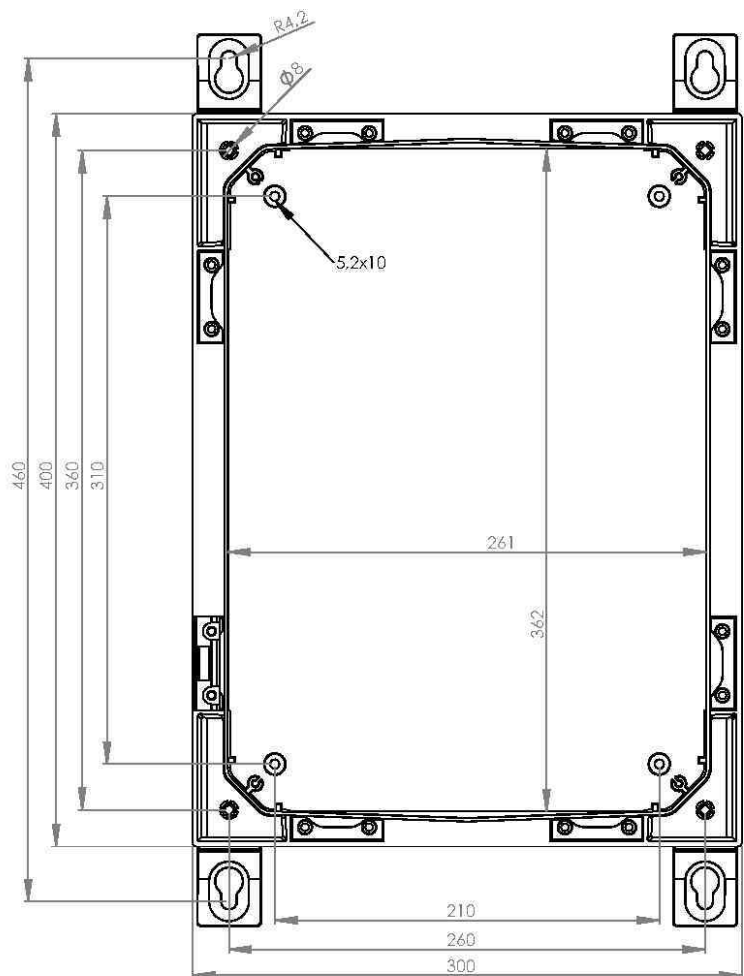

| Dimensions : | Height | Width | Depth |
|--------------|--------|-------|-------|
| mm :         | 400    | 300   | 150   |
| inch :       | 15.75  | 11.81 | 5.91  |

#### Materials :

|                   |               |
|-------------------|---------------|
| Material :        | Polycarbonate |
| Base colour :     | RAL_7035      |
| Cover colour :    | Smoked grey   |
| Gasket material : | Polyurethane  |

#### Temperatures :

|                               |             |
|-------------------------------|-------------|
| Temperature °C (continuous) : | -40 ... 80  |
| Temperature °F (continuous) : | -40 ... 175 |

#### Accessories :

|                 |                                                                           |
|-----------------|---------------------------------------------------------------------------|
| DRS ARCA 403015 | DIN rail frame set (385 x 285 x 35)                                       |
| RCS ARCA 4030   | Rain canopy set for size 4030 and 3030 (30 x 300 x 20)                    |
| IDS ARCA 4030   | Inner door set (385 x 285 x 35)                                           |
| PMK ARCA 30     | PoleMounting kit, for pole ø100-300mm (385 x 285 x 35)                    |
| DSP ARCA VLS    | Door stopper ARCA, vertical, left, small (15 x 104 x 16)                  |
| MPMP ARCA 4030  | Mounting plate multiperforated (350x250x2 mm - ø3.6 mm) (350 x 250 x 1.5) |
| DSP ARCA VRS    | Door stopper ARCA, vertical, right, small (15 x 104 x 16)                 |
| MPS ARCA 4030   | Mounting plate (350x250x2 mm) (350 x 250 x 2)                             |
| MPP ARCA 4030   | Mounting plate perforated (350x250x2 mm - 26x11 mm) (350 x 250 x 2)       |
| MPX ARCA 4030   | Mounting plate (350x250 mm) (350 x 250 x 5)                               |

#### Ratings :

|                                         |                   |
|-----------------------------------------|-------------------|
| Ingress protection (EN 60529):          | IP66;             |
| Impact Resistance (EN 62262):           | IK09;             |
| electrical_insulation :                 | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815) : | Yes               |
| UV resistance :                         | UL 746C           |
| Flammability Rating :                   | UL 94 5VA         |
| Glow Wire Test (IEC 695-2-1) °C :       | 960C              |
| UL Type                                 | 1, 4, 4X, 12, 13  |

**Certificates :**  
Certificate FI 40467