


CUBE20S POWER MODULE

24VDC

Power module
Expansion module
for external voltage supply

[Link to Product](#)

Illustration

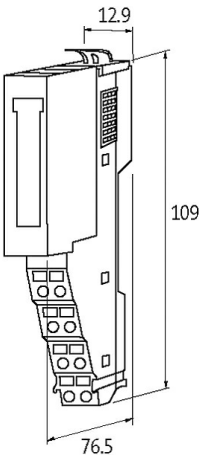

Product may differ from Image

Approvals



General data

Protection	IP20
Connection	Spring clamp terminals: 0.08...2.5 mm² (AWG 28...14)
Mounting method	DIN-rail mountable (EN 60715)
Temperature range	0...+60 °C (storage temperature -25...+70 °C)
Dimensions H×W×D	109×12.9×76.5 mm

Module supply

Operating voltage	max. 28.8 V DC
-------------------	----------------

Total current	max. 10 A
---------------	-----------

Output

Output current (I/Os /Backplane)	10/0 A
----------------------------------	--------

Output voltage (I/Os /Backplane)	24 V AC
----------------------------------	---------

Commercial data

country of origin	TH
-------------------	----

customs tariff number	85369010
-----------------------	----------

EAN	4048879422888
-----	---------------

eClass	27242610
--------	----------

Packaging unit	1
----------------	---