

Keystone Module RJ45 jack to RJ45 jack Cat.6A 90° angled

Description

This module by Delock can be used to extend twisted pair cables. With its standardised dimensions it can be used for easy snap-in mounting in e.g. a Keystone patch panel, face plate or surface-mount box.



Item no. 86997

EAN: 4043619869978

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
1 x RJ45 jack >
1 x RJ45 jack 90° angled
- Cat.6A specification
- Shielded (STP)
- Contacts gold-plated
- For Keystone ports with 19.2 x 14.9 mm
- Operating temperature: -40 °C ~ 70 °C
- Material: zinc die cast
- Colour: silver / white
- Dimensions (LxWxH): ca. 33.8 x 19.4 x 16.7 mm


System requirements

- A free RJ45 plug

Package content

- Keystone module

Images

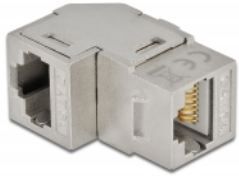

General

Specification:	Cat. 6A
Style:	angled 90° both sides identical

Interface

Connector 1:	1 x RJ45 jack
Connector 2:	1 x RJ45 jack

Technical characteristics

Operating temperature:	-40 °C ~ 70 °C
------------------------	----------------

Physical characteristics

Material:	zinc die cast
Length:	33.8 mm
Width:	19.4 mm
Height:	16.7 mm
Colour:	white silver

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

