

Easy 45 Module Power Retractable Cable DC 5.5 x 2.1 mm female / female white

Description

This power cable by Delock can be used to supply power to devices with an existing DC plug. The simple snap-in mechanism ensures that the module is firmly in place and can be easily removed if necessary.

Flexible

The power cable can be pulled out in six steps and thus offers different cable lengths, depending on requirements. If the cable is not needed, it is neatly rolled up and stowed away.

Easy 45 connects

Easy 45 is a variable, modular system that allows components such as sockets, HDMI or USB connections to be added according to your needs. The Easy 45 modules are standardised and can be mounted in various module holder or cable ducts. Easy 45 builds the interface between electrical, network and system installation and many peripheral devices such as TV, monitors, printers, laptops and much more.



Item no. 81376

EAN: 4043619813766

Country of origin: China

Package: Box

Technical details

- Connectors:
external: 1 x DC 5.5 x 2.1 mm female
internal: 1 x DC 5.5 x 2.1 mm female
- Voltage: max. 12 V
- Current: max. 1.5 A
- Cable gauge: 24 AWG
- Length incl. connectors:
Host-cable ca. 12 cm
Device-cable ca. 50 cm (extended)
- Suitable for module holder Delock Easy 45
- Suitable for 45 mm cable duct with minimum depth 45 mm
- Module size: 22.5 x 45 mm
- Dimensions (LxWxH): ca. 45.0 x 22.5 x 47.0 mm
- Colour: white


System requirements

- A free module port Delock Easy 45

Package content

- Easy 45 module retractable cable

Images

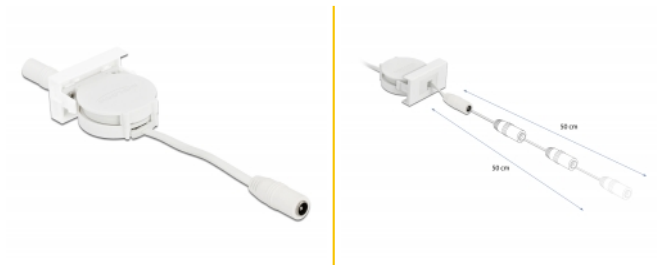

Interface

Connector 1:	1 x DC 5.5 x 2.1 mm female
Connector 2:	1 x DC 5.5 x 2.1 mm female

Technical characteristics

Voltage:	12 V
----------	------

Physical characteristics

Connector color:	white
Length:	47 mm
Width:	22.5 mm
Colour:	RAL 9003 Weiß

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

