

図番	改訂	ページ
NE-002D-W18	A	1 / 1

SPECIFICATIONS


[1.General Specifications]

Product Name	Wall Mount Bracket
Model	NE-002D
Mounting Location	Indoor
Mounting Direction	Upright
Mass (Tolerance $\pm 10\%$)	0.034kg
Outer Dimensions	Refer to the [2.Outer Dimensions]
Remarks	There are no contents of controlled substances exceeding the threshold for the RoHS Directive.

[2.Outer Dimensions]


[mm]

Material: PC
Color: Off Dark Gray

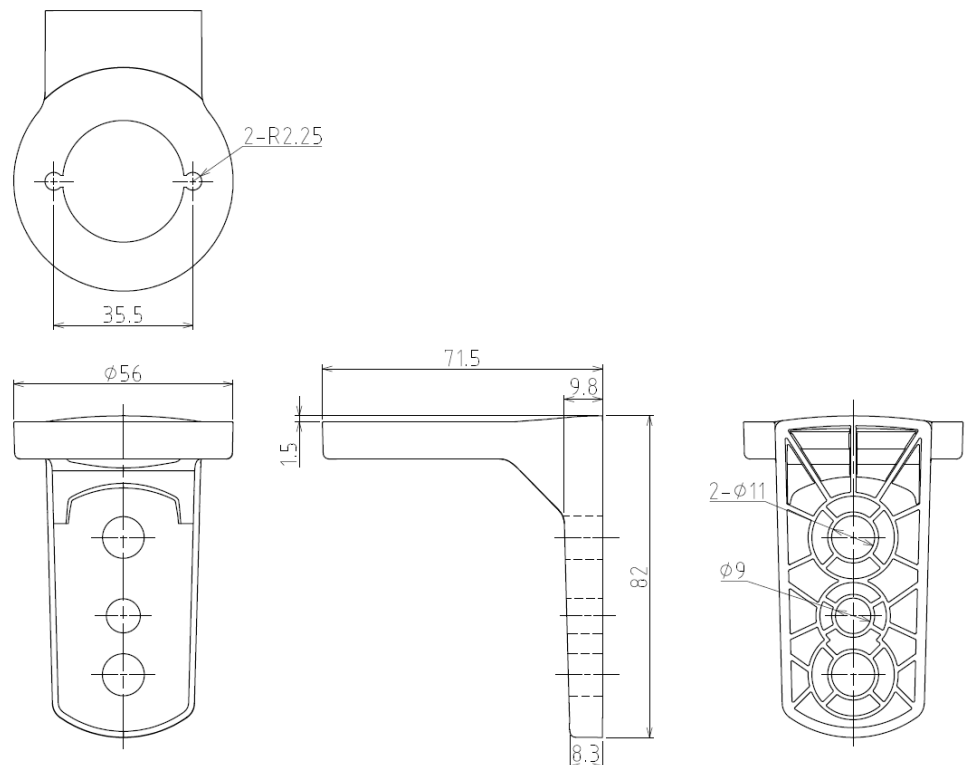

[3.Mounting Dimensional Drawing]

[mm]

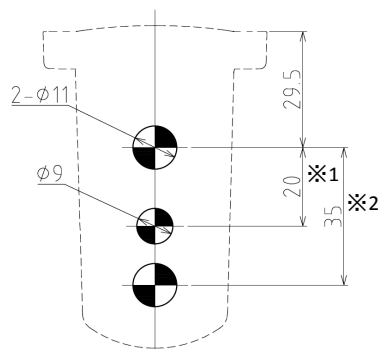

Screw/Nut
※1: M8×2pcs
※2: M10×2pcs

Recommended Torque
2.4N・m