

RJ45 Network Cable Cat.6A plug to plug with curved latch U/FTP Slim 0.3 m green

Description

This network cable by Delock can be used to connect different networking devices, e.g. a NIC to a switch or a patch panel.

Slim patch cable

The thin patch cables are characterised by their small cable diameter and enable flexible and space-saving cabling in the network cabinet.

With curved latch

The RJ45 plug is designed with a curved latch that gives way when the plug is pulled out and therefore cannot be damaged.



Item no. 80363

EAN: 4043619803637

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
 - 1 x RJ45 plug
 - 1 x RJ45 plug
- Cat.6A specification
- Data transfer rate up to 10 Gbps
- Bandwidth: 500 MHz
- Shielded (U/FTP)
- RJ45 plug with curved latch
- Slim
- Cable gauge: 28 AWG
- Contacts gold-plated: 50 µ"
- Cable diameter: ca. 4.9 mm
- Cable jacket material: LSZH
- Colour: green
- Length: ca. 0.3 m



System requirements

- A free RJ45 jack

Package content

- RJ45 cable

Images

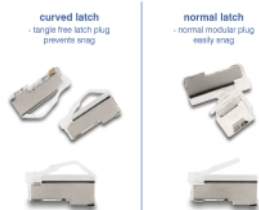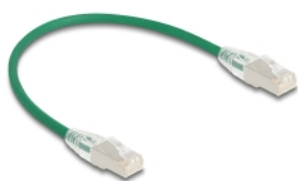

General

Specification:	Cat. 6A
Style:	both sides identical

Interface

Connector 1:	1 x RJ45 male
Connector 2:	1 x RJ45 male

Physical characteristics

Cable gauge:	28 AWG
Material:	LSZH (halogen-free)
Shielding:	U/FTP
Length:	0.3 m
Colour:	green
Cable diameter:	4.9 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de