

Keystone Module RJ45 jack to LSA Cat.6A toolfree with blue twist lock

Description

This module by Delock can be used to connect a network cable and is suitable for easy snap-in mounting in various holders, such as keystone patch panels, face plates or surface-mount boxes.

Rotatable attachment

The installation of the cables is quick and toolfree and with the rotatable lock of the attachment, the module is firmly closed.



Item no. 88130

EAN: 4043619881307

Country of origin: China

Package: Poly bag


Technical details

- Connectors:
 - 1 x RJ45 jack
 - 1 x LSA (toolfree)
- Cat.6A specification
- Unshielded (UTP)
- With twist lock
- TIA-568A/B pinout
- Suitable for round cables with max. cable diameter of 6 mm (26 - 22 AWG)
- For Keystone ports with 19.2 x 14.9 mm
- Material: plastic
- Colour: blue / white
- Dimensions (LxWxH): ca. 30.5 x 22.5 x 19.2 mm

Package content

- Keystone module

Images

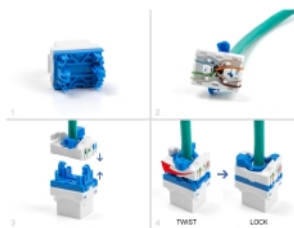

General

Specification:	Cat. 6A
----------------	---------

Interface

Connector 1:	1 x RJ45 jack
Connector 2:	1 x LSA (toolfree)

Physical characteristics

Material:	Plastic
Length:	30.5 mm
Width:	22.5 mm
Height:	19.2 mm
Colour:	blue white
Cable diameter:	6 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

