

Contact terminal A KT-120 L3 E02-30

Item KT-120L3E02-30




GO TO PRODUCT



ingun[®]

Partner for Future Technology

INGUN SELECTION

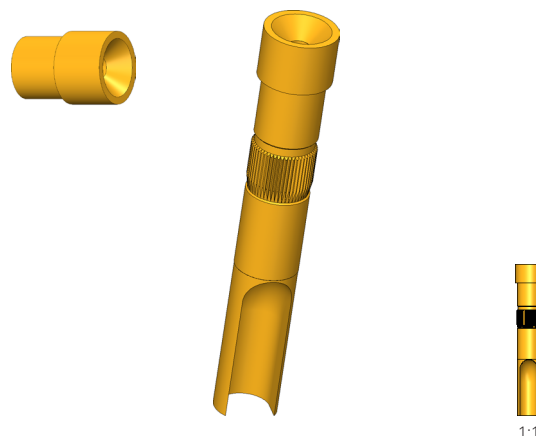

1:1

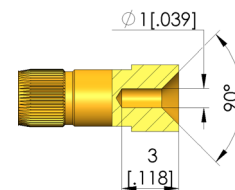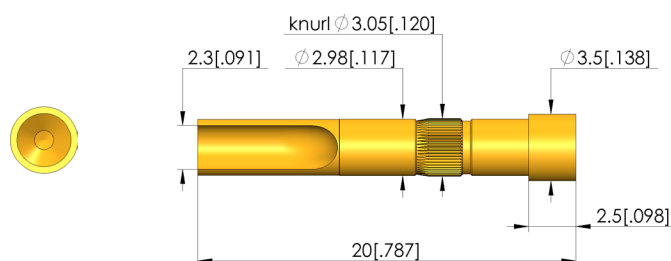

General data

Product group:
Series:
Sub-series:
Grid:
Type of contact terminal connection:
Magnetic:
Installation type:
Quick-exchange system:
Surface area:
Material:
Knurl:
RoHS-compliant:

Contact terminals (KT)
KT-120
KT-120
4 mm [157 mil]
Solder connection
Yes
Press-in
No
A gold
1 brass
Yes
RoHS-3;6c

Mounting hole

Mounting hole in CEM1:
Mounting hole in FR4:

3.00 - 3.02 mm [.118 - .118 in]
3.00 - 3.02 mm [.118 - .118 in]

Mechanical data

Collar height:
Total length:
Shaft diameter:
Latching lug:

02
20 mm [.787 in]
2.98 mm [.117 in]
No

Tip style data

Tip style:
Tip diameter:
Bore ϕ in tip style:

43 inverse cone with chamfered bore
3.5 mm [.137 in]
1 mm [.039 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com