

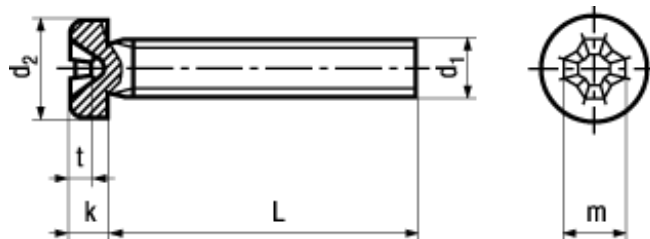


SN 213307

~ISO 7048

4.8

Norma ritirata

**BN 381****Viti a testa cilindrica**

con impronta a croce Phillips forma H

Acciaio 4.8

zincato bianco

[3D Cadenas](#)

Tutte le misure con filettatura quasi completa

Article#	d ₁	d ₂ max.	k max.		m~	t min.	L
1152173	M2	3,8	1,4	1	2,3	0,9	3
1152181							4
1152203							5
1152211							6
1152238							8
1152246							10
1152254							12
1152262							(14)
1152270							16
1152289							20
3056341	M2,5	4,5	1,8	1	2,7	1,2	3
1152297							4
1152300							5
1152319							6
1152327							8
1152335							10
1152343							12
1152351							(14)
1152378							16
1152386							20
2096714							30
3056342	M3	5,5	2	2	3,5	0,86	3
1152394							4
1152408							5

Article#	d ₁	d ₂ max.	k max.		m~	t min.	L
1152416	M3	5,5	2	2	3,5	0,86	6
1152424							8
1152432							10
1152440							12
1152459							(14)
1152467							16
1152475							(18)
1152483							20
1152491							(22)
1152505							25
1152513							30
3186788							35
3186789							40
3186790							45
1435590							50
3056343	M4	7	2,6	2	4,1	1,45	4
1152521							5
1152548							6
1152556							8
1152564							10
1152572							12
1152580							(14)
1152599							16
1152602							(18)
1152610							20
1152629							(22)
1152637							25
1152645							30
3186793							35
3091628							40
3092836							45
3092837							50
1435604							60
3056344	M5	8,5	3,3	2	4,8	2,14	5
1152653							6
1152661							8
1152688							10
1152696							12
1152718							(14)
1152726							16
1152734							(18)

Article#	d ₁	d ₂ max.	k max.		m~	t min.	L
1152742	M5	8,5	3,3	2	4,8	2,14	20
1152750							25
1152769							30
1152777							35
1152785							40
1435612							60
1152793	M6	10	3,9	3	6,2	2,25	8
1152807							10
1152815							12
1152831							16
1152866							20
1152874							25
1152882							30
1152890							35
1152904							40
3092840							50
1435620							60