


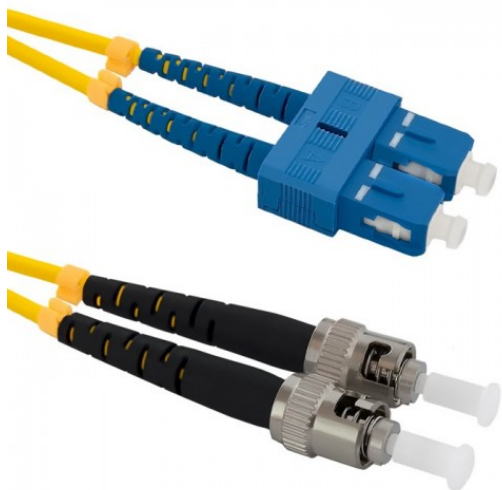

Patchcord fiber optic SC/UPC - ST/UPC | Singlemode | 9/125 | G652D | Duplex | 3m

Product code: 54061

Patchcord fiber optic singlemode
Connectors: SC/UPC - ST/UPC
Standard: G652D
Diameter cable: 3.0 mm
Cable length: 3 m

Technical data

Type connectors	SC/UPC - ST/UPC
Type patchcord	Singlemode
Type of fiber optic transmission	Duplex
Standard fiber	G652D
Fiber type	9/125
Diameter of the mode field	9 m
Diameter fibers sheath	125 m
Sheath	LSZH
Diameter cable	3.0 mm
Insertion loss	<0.3 dB
Return loss	>55 dB
Cable length	3 m
Reinforcing element	Aramid fiber
Colour	Yellow
Additional information	Easy installation and handling on high speed fiber optical transmission networks. LSZH - Outside fireproof cable sheath, which the fire does not emit harmful gases. The product individually tested.
Package	Polybag
Gross weight	0,065 kg
EAN code	5901878540610

	100 Mb Ethernet	1 Gb Ethernet	10 Gb Ethernet	40 Gb Ethernet	100 Gb Ethernet
OM2 (50/125)	2km	550m	82m	Nie wspiera	Nie wspiera
OM3 (50/125)	2km	800m	300m	100m	100m
OM4 (50/125)	2km	1100m	550m	125m	125m

