

Bracket

MULTI-MOUNT-14(45x75)
Order Number: 70114096

Main Parameters (*)	min	typ	max	Unit
Operating Voltage			0	V DC
Operating Temperature	-20		50	°C
Storage Temperature	-50		70	°C

Main Data

Warranty	1 years
----------	---------

Technical Parameters

RoHS	yes
------	-----

Mechanical Parameters

Size	Ø45x75 mm
Material	aluminium
Housing Color	black
Weight	141 g

Mount Parameter

Total Height (h1)	75 mm
Height to Laseraxis (h2)	61.5 mm
Height of Base (h3)	25 mm
Mount Diameter (d1)	Ø 14 mm
Diameter of Base (d2)	Ø 45 mm
Width of Mount (b)	26 mm
Height of Mount (g)	50 mm
Height of Mount Head (k)	50 mm
Depth of Mount (t)	15 mm

Angle of Rotation Alpha (α)	360°
Angle of Rotation Beta (β)	± 90°


(*) Over the complete operating temperature range

Features



- Anodized aluminium
- Very robust
- For industrial applications

Picture

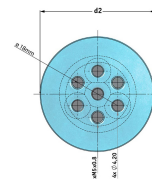

Safety Label



Valid Revision

1 | 21-JUN-2024