


|                        |                                                                                                                                                                                                                                                                                                                                                                         |
|------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| article#               | <b>11391-5</b>                                                                                                                                                                                                                                                                                                                                                          |
| article description    | <b>CEE-receptacle wall mount 20A 2P3W 5h IP44 UL</b>                                                                                                                                                                                                                                                                                                                    |
| description long       | CEE-receptacle wall mount 20A 2P3W 5h IP44 UL (PCE320RS5S)<br>housing material: PA6<br>rated current: 20A<br>number of poles: 2P3W (3p)<br>clock position: 5h<br>rated voltage: 277Vac<br>contacts: brass<br>connection technology: screw terminals<br>IP protection class: IP44<br>according to UL1682<br>UL-product category: QLIW / QLIW7<br>UL-file number: E252008 |
| GTIN (EAN)             | 9003399336386                                                                                                                                                                                                                                                                                                                                                           |
| country of origin      | AT                                                                                                                                                                                                                                                                                                                                                                      |
| customs number         | 85366990                                                                                                                                                                                                                                                                                                                                                                |
| net weight             | 0.202 kg                                                                                                                                                                                                                                                                                                                                                                |
| packaging quantity     | 5                                                                                                                                                                                                                                                                                                                                                                       |
| minimum order quantity | 5                                                                                                                                                                                                                                                                                                                                                                       |

|                                               |                   |
|-----------------------------------------------|-------------------|
| ETIM 9.0                                      | EC001321          |
| Model                                         | Surface mounted   |
| Amperage according to UL/CSA (for UL-version) | 20 A              |
| Clock hour position                           | 5 h               |
| Identification colour                         | Grey              |
| Degree of protection (IP)                     | IP44              |
| Connection system                             | Screwed terminal  |
| Cable entry                                   | Gland nut         |
| Material                                      | Plastic           |
| Contact material                              | CuZn              |
| Surface treatment contacts                    | Untreated         |
| Type of fastening                             | External mounting |

|                        |                     |
|------------------------|---------------------|
| a                      | 5.63 inch           |
| b                      | 3.98 inch           |
| wire flexible          | 16-12 AWG           |
| wire solid             | 1-4 mm <sup>2</sup> |
| contact screws         | 8.85 lbf-in         |
| connecting screws      | 9.74 lbf-in         |
| dismantling length     | 1.97 inch           |
| stripping length       | 0.39-0.47 inch      |
| temperature resistance | -13 – 176 °F        |

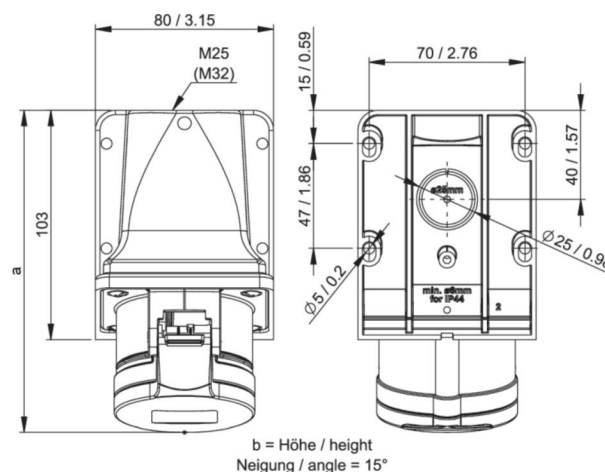

<https://www.pcelectric.at/shop/en/?func=detail&artnr=11391-5>