


LED STRIP 120LED/M 1M • 24V • 17W • 2100K MEAT • IP20 • 1300LM • RA80 • 8MM

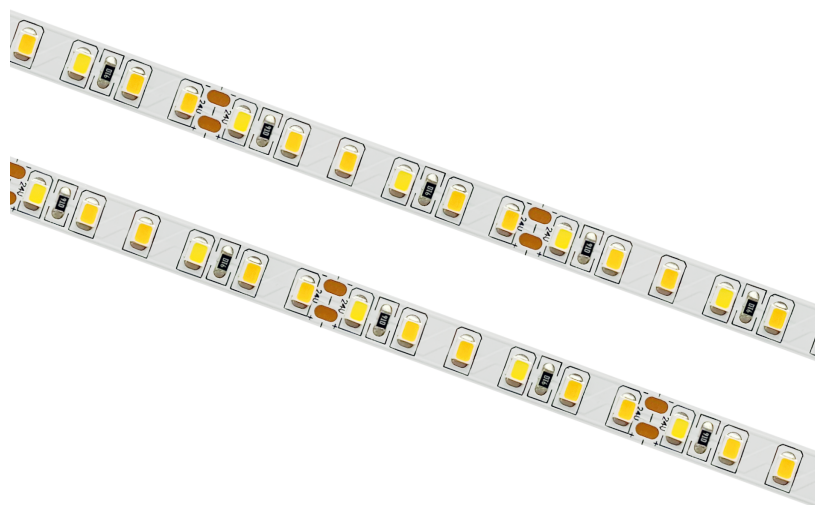

17W /m
24V DC
5cm cutting length
3oz 8mm FPC
Ra>80
30m reel for IP20, 10m for IP66
Warranty 3 years

High quality LED strip for professional use.
A special color of light that emphasizes the aesthetic and color values of meat and its products. Constructed alternately of two LEDs with a color specially selected to illuminate meat with high intensity of pink color, and one white 3000K LED. Two layers of PCB 10mm width, with 3oz copper paths characterized by a lower voltage drop and lower operating temperature. On a base using adhesive tape 3M 300 LSE.

Specification

Parameter	Value	ETIM ID
Symbol	SPA-120-MEAT24	
EAN13	5901289754910	
ETIM CLASS	Light ribbon-/hose/-strip	EC002706
Power [W]	17	EF008319
Voltage [V]	24	EF008856
cutting length [cm]	5	EF008320
Colour of light	White	EF009350
Model	Tape	EF000010
Number of nodes per meter	120	EF008340
Voltage type	DC	EF000187
Beam angle [°]	120	EF000128
Wskaźnik oddawania barw CRI	>80	EF000442
With Self-adhesive	tak	EF000434
Colour temperature [K]	2100	EF009346
Degree of protection	IP20	EF005474
Suitable for use		
Luminous flux [lm]	1300	EF010867
Rated life time L70/B50 at 25 °C [h]	50000	EF011870
Width [mm]	8	EF000008
Height/depth [mm]	1.5	EF001456

Dimensions

