

USB 3.1 Gen 1 Adapter USB Type-C™ to 3 x USB 3.0 Type-A Hub + 1 x VGA (DP Alt Mode)

Description

This adapter by Delock is suitable for the connection to a computer with USB-C™ interface and DisplayPort alternate mode support. It extends the system by three USB 3.0 Type-A interfaces as well as one VGA interface.



Item no. 63932

EAN: 4043619639328

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 1 x SuperSpeed USB (USB 3.1 Gen 1) USB Type-C™ male >
 - 3 x SuperSpeed USB (USB 3.1 Gen 1) Type-A female
 - 1 x VGA 15 pin female
- Chipset: VL100, VL813, ITE6516
- DisplayPort 1.2 and SuperSpeed USB specification
- Resolution up to 1920 x 1080 @ 60 Hz (depending on the system and the connected hardware)
- USB bus powered
- Plug & Play
- 1 x ferrite core
- Metal housing
- Cable length without connectors: ca. 15 cm
- Colour: black

System requirements


- Android 6.0 or above
- Chrome OS
- Linux Kernel 3.19 or above
- Mac OS 10.12 or above

- Windows 7/7-64/8.1/8.1-64/10/10-64
- Windows 10 Mobile
- PC or laptop with a free USB Type-C™ port and DisplayPort alternate mode or
- PC or laptop with a free Thunderbolt™ 3 port

Package content

- USB-C™ to 3 x USB-A + VGA adapter

Images

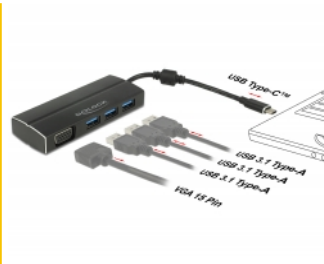

General

Function:	Plug & Play
Supported operating system:	Chrome OS Linux Kernel 3.19 or above Mac OS 10.12 or above Windows 10 32-Bit Windows 10 64-Bit Windows 10 Mobile Windows 7 32-Bit Windows 7 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit

Interface

Output:	1 x VGA 15 pin female
Input:	1 x USB 5 Gbps USB Type-C™ male

Technical characteristics

Data transfer rate:	5 Gbps
---------------------	--------

Physical characteristics

Material:	Aluminium
Colour:	black
Cable length without connectors:	15 cm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de