

Dual White

315 140LED



CRI Option

- 80+
- 90+

 
PCB Thickness

- 2oz
- 3oz
- 4oz-on request

PCB Color

- White
- Black
- Golden

Color Option



Technical Data

Voltage	Code	Color	Watts	Lumen	Efficiency	Pitch	Width
24VDC	H140210-CCT	2700K	4.8	417	87	100mm	10mm
		6500K	4.8	480	100		
		Mix 4000K	Max. 9.6	912	95		


The above measurements are based on IP20.

The above measurements can have a 10% tolerance.

Main Features

- Side viewing turnable white LED Strip Lights.
- High density 140 LED on single line.
- 24Vdc input, less heat and voltage drop then 12Vdc.
- Ideal for office, residential, retail and industry lighting.

Dimensions

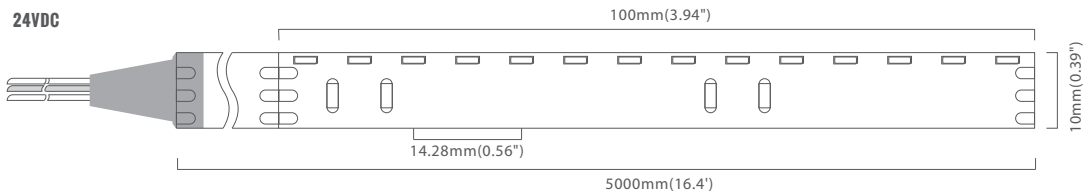


Available Waterproof Ways

IP Rating	20	54A	54B	65A	65B	67	68
Section							
Material	none	Silicone glue on surface	PU glue on surface	Inject with Heat Shrink tube	Inject with silicone tube	Silicone extrusion	Silicone extrusion

Accessory



 HH-1616



HH-1707D



HH-1707