

Panel Mount coupler USB 5 Gbps Type-A female to USB Type-A female conical

Description

This module with mounting holder by Delock can be used to extend USB cables and is suitable for installation in housings or switch cabinets.



Item no. 67165

EAN: 4043619671656

Country of origin: China

Package: Poly bag


Technical details

- Connectors:
 - 1 x USB 5 Gbps Type-A female
 - 1 x USB 5 Gbps Type-A female
- Data transfer rate up to 5 Gbps
- Pin assignment:
 - 5 SSRX- 8
 - 6 SSRX+ 9
 - 8 SSTX- 5
 - 9 SSTX+ 6
- With Keystone holder for panel mount
- Integrated name plate
- Panel cut-out (WxH): ca. 16.8 x 22.3 mm
- Countersink for conical screws, distance ca. 28.9 mm
- Mounting hole diameter: ca. 3.3 mm
- Screw type: #4-40 UNC
- Operating temperature: -10 °C ~ 60 °C
- Material: zinc diecast / plastic
- Colour: silver / white
- Dimensions (LxWxH): ca. 35.2 x 19.2 x 35.5 mm

Package content

- USB Keystone module with holder
- 2 x screws

Images

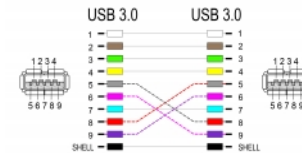

General

Style:	both sides identical
--------	----------------------

Interface

Connector 1:	1 x USB 5 Gbps Type-A female
Connector 2:	1 x USB 5 Gbps Type-A female

Technical characteristics

Operating temperature:	-10 °C ~ 60 °C
------------------------	----------------

Physical characteristics

Material:	zinc die cast
Length:	35.2 mm
Width:	19.2 mm
Height:	35.5 mm
Colour:	white silver

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

