

# Keystone Module RJ45 jack Cat.8.1 toolfree

## Description

This module by Delock can be used to connect twisted pair cable to an RJ45 jack. With its standardised dimensions it can be used for easy snap-in mounting in e.g. a Keystone patch panel, face plate or surface-mount box.



**Item no. 86488**

EAN: 4043619864881

Country of origin: China

Package: Zip poly bag

## Technical details

- Connectors:  
external: 1 x RJ45 jack (8P/8C) >  
internal: LSA (toolfree)
- Cat.8.1 specification
- GHMT certified: 2 Connector Channel Link ISO/IEC TR 11801-9901 Ed.1.0 (2014-08)
- Supports PoE / PoE+
- Shielded (STP)
- Material: zinc die cast
- For solid or stranded wire up to 0.644 mm (22 - 24 AWG)
- For cable diameter from 5.5 - 9.0 mm
- For Keystone ports with 19.2 x 14.9 mm
- Dimensions (LxWxH): ca. 41.6 x 16.5 x 22.5 mm

## System requirements

- A free RJ45 plug



## Package content

- Keystone module

- Cable manager
- Copper foil
- Zip-tie

---

## Images

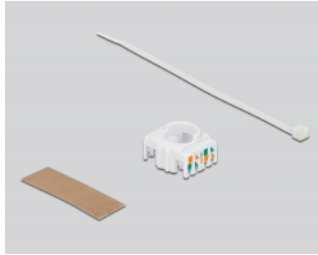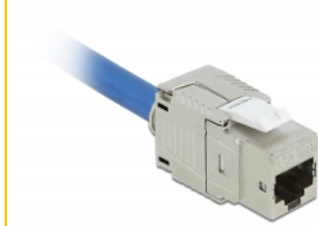

## General

|                               |                 |
|-------------------------------|-----------------|
| Suitable for conductor gauge: | 22 - 24 AWG     |
| Mounting type:                | Keystone module |
| Specification:                | Cat. 8.1        |

## Interface

|           |               |
|-----------|---------------|
| External: | 1 x RJ45 jack |
| Internal: | 1 x LSA block |

## Physical characteristics

|                   |               |
|-------------------|---------------|
| Housing material: | zinc die cast |
| Shielding:        | shielded      |
| Length:           | 41.6 mm       |
| Width:            | 16.5 mm       |
| Height:           | 22.5 mm       |

## Manufacturer information

|             |                   |
|-------------|-------------------|
| Street      | Beeskowdamm 13/15 |
| Postal code | 14167             |
| City        | Berlin            |
| Country     | Deutschland       |
| E-Mail      | info@delock.de    |
| Website     | www.delock.de     |

